


Project Name

Location

Prepared By

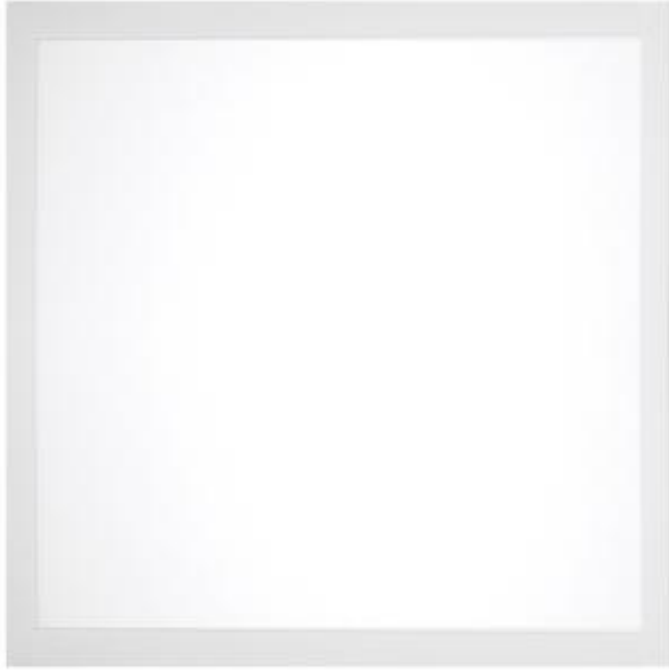

NUVO 65-585R1

2X2 LED EM BACKLIT FLAT PANEL

Notes

[www] 06-17-2023 22:42:03

General

Status	Active
Fixture Type	Backlit Flat Panel
Finish	White
Wattage	20W/30W/40W
Lumen Output	2200L-4600L
CCT (Kelvin)	3500K/4000K/5000K
IP Rating	IP20
Indoor or Outdoor Fixture	Indoor

Smart Product Info

IOT Enabled	No
-------------	----

Specifications

Technology	LED
Color Temperature	Warm to Cool White
CRI	80+
Voltage	100V-347V
Beam Angle	120
Rated Hours	50000
Operating Temperature	-17C (+1.4F) to +45C (+113F)
Dimmable	Yes-Dimmable
Dimming Note	0-10V Dimming Only
Photocell or Sensor	No Photocell
Lens Material	Poly methyl methacrylate (PMMA)
Surge Protection	Built-in surge protection - 2KV
Weight (lb.)	7.28
Material	Aluminum / Steel

Dimensions

Height (in.)	2.88
Width (in.)	23.75
Length (in.)	23.75

Compliance

Safety Listing	cETLus
Location Rating	Damp
Energy Star	No
DLC Approved	Yes
DLC ID	S-B9J4TR
NSF Approved	Yes
Air Tight Rated	No
IC Rated	Yes
CA T20 / T24 Rationale	T20 Exempt - Fixtures Not Regulated
California Status	Lawful for sale in California
Title 20 / 24 Status	Lawful for sale
California Prop 65	Lead
RoHS Compliant	Yes
FCC Compliant	Yes
Flicker Free	Yes
SDS Sheet	LED_Fixture

Additional Information

Additional Information

Driver Specs - VDC38-48V;
430/620/810mA

Warranty

5 Year Limited - Fixtures

Copyright 2020 Satco Products, Inc.
All Rights Reserved

For More Information Visit:
<http://www.satco.com/>

