




110 Heartland Blvd
 Brentwood, NY 11717
 Tel: (800)437-2826 Fax: (631)243-2027

Brand: SATCO

Type/Color : F15T12/WW

Item NO. S26564

SPECIFICATION OF FLUORESCENT LINEAR LAMPS

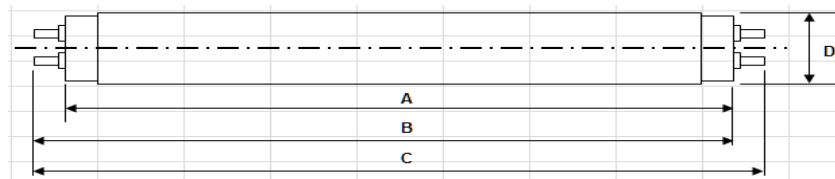

TYPE		Lamp dimension (mm.)						
F15T12/WW		Nominal	A	B		C	D	Base
CRI	Color	dimensions	Max.	Min.	Max.	Max.	Max.	
52	3000K	38 mm. x 450 mm.	437.4	442.1	444.5	451.6	40.5	G13

Electrical characteristic						
Nominal wattage (W.)	Lamp volt. (V.)	Lamp current (mA.)	Operation method	Frequency (Hz)	Lumen	Rated avr. Life (Hrs.)
15	41-51	335	Preheat	50/60	750	8,000