




110 Heartland Blvd
 Brentwood, NY 11717
 Tel: (800) 437-2826 Fax: (631) 243-2027

Brand: SATCO

Type/Color : F30T12/D35/RS

Item NO. S26575

SPECIFICATION OF FLUORESCENT LINEAR LAMPS

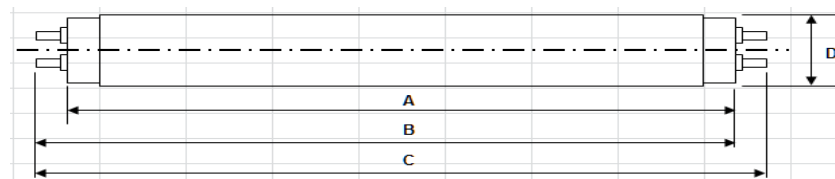

TYPE		Lamp dimension (mm.)						Base
CRI	Color	Nominal dimensions	A Max.	B Min. / Max.	C Max.	D Max.		
75	3500K	38 mm. x 900 mm.	894.6	899.3 / 901.7	908.8	40.5	G13	

Electrical characteristic						
Nominal wattage (W.)	Lamp volt. (V.)	Lamp current (mA.)	Operation method	Frequency (Hz)	Lumen	Rated avr. Life (Hrs.)
30	71-91	405	Preheat /Rapid start	50/60	2,350	16,000