




110 Heartland Blvd
 Brentwood, NY 11717
 Tel: (800) 437-2826 Fax: (631) 243-2027

Brand: SATCO

Type/Color : F40T12/950 DSGN50

Item NO. S26610

SPECIFICATION OF FLUORESCENT LINEAR LAMPS

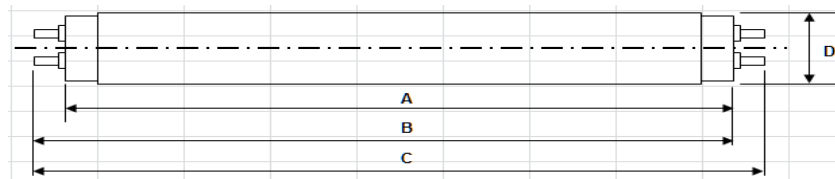

TYPE		Lamp dimension (mm.)						Base
F40T12/950	Nominal	A	B		C	D		
CRI	Color	dimensions	Max.	Min.	Max.	Max.	Max.	
90	5000K	38 mm. x 1200 mm.	1199.4	1204.1	1206.5	1213.6	40.5	G13

Electrical characteristic						
Nominal wattage	Lamp volt.	Lamp current	Operation method	Frequency	Lumen	Rated avr. Life
(W.)	(V.)	(mA.)		(Hz)		(Hrs.)
40	93-113	430	Preheat /Rapid start	50/60	2,200	20,000