

Value unit – Excellent for low profile, small lightweight boxes



The **CS-5050AC Semi-Automatic Uniform Carton Sealer with Easy Manual Carton Size Adjustment** has a side-drive belt design. The machine comes complete with infeed / exit conveyors, casters, power cord and plug.

The operator simply folds the top flaps of the corrugated carton and feeds it into the machine. The CS-5050AC applies a single tape to both the top and bottom of the case simultaneously. The CS-5050CA can be easily adjusted in only seconds to process a different size carton. Excellent for low profile, small, lightweight boxes.

Standard Features:

- Side Pressure Rollers to Close Box Top
- 2 Side Drive Belts for Positive Feed
- Infeed / Exit Conveyors
- Casters


Optional Features:

- 3" (72mm) Tape Heads
- Stainless Steel Frame

SPECIFICATIONS	
CARTON SIZE	
LENGTH:	5.9" TO INFINITE
WIDTH:	4.7" MIN TO 19.6" MAX
HEIGHT:	4.7" MIN TO 19.6" MAX
MACHINE SIZE:	57"L X 36"W X (48"-64")H
MACHINE SPEED:	65.6FT./MIN UP TO 15 CARTONS PER MINUTE PRODUCTION RATE DPENDS ON CARTON SIZE AND OPERATOR DEXTERITY
ELECTRICAL:	110V, 1 PHASE, 10 AMP
WEIGHT:	286-LBS (SHIPPING WEIGHT: 336-LBS)
MAX BOX WEIGHT:	55-LBS
TAPE HEAD SPECS:	2" (48MM) WIDE – 1,000 YARD OR 1,500 YARD ROLLS



Cutter Blade Protection Cover

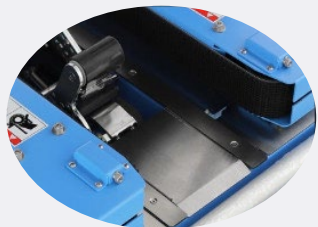

Easy Adjustment for Conveyor Belts



Easy Tape Head Changeout

Tape Head w/ Roller

Top Flap Compression
Rollers

Side Drive Belt

- 4 Belt Design
- Belt Speed (65FPM)

Locking Casters

Height Adjustment Crank

Infeed / Exit Conveyors

