




Longer Seal Lengths for Special Projects

- Longer seal lengths for specialized sealing needs
- Automatic impulse sealing with precise electronic control
- Dual mode operation: automatic or manual
- Foot switch allows both hands to be free
- 3 separate control settings for sealing time, recycle time, and congealing time
- Equipped with either two or three electromagnets
- Includes electric foot switch and worktable
- Special order units w/ exception of W-755AA

We now carry extra-wide seal bars for our popular W-Series automatic sealers. The extra-wide seal bars of the W-Series automatic sealers come in 30", 35", 47", and 59" sealing lengths. W-Series automatic sealers are designed for the continuous sealing of thermoplastic materials. Depending on the model of the sealer, materials up to 59" wide and 15mil total thickness can be sealed with a seal width of 2.7mm or 5mm. Unit is controlled by a plug-in transistorized circuit board. Equipped with an electronic timer and electromagnet, once correct settings have been established, consistent seals will be maintained automatically.

The extra-wide seal bars are equipped with either a double or triple electromagnet (solenoid) to ensure the most stable pressure for the extra-wide seal bars.

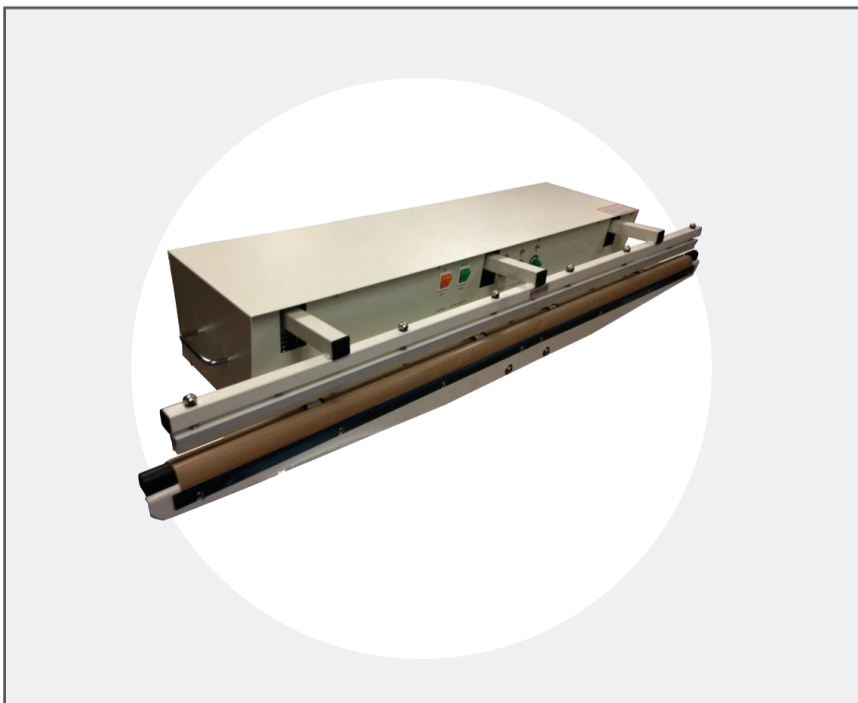

Model #	Seal Length	Seal Width	Power	Weight (lbs)	Dimensions
W-755AA*	30"	5mm	2600W	82	33" x 15" x 10"
W-900AA W-905AA	35"	2.7mm 5mm	2942W	90	39" x 15" x 10"
W-1200AAA W-1205AAA	47"	2.7mm 5mm	4125W	97	51" x 15" x 10"
W-1500AAA W-1505AAA	59"	2.7mm 5mm	4290W	114	63" x 15" x 10"

*Stock unit