
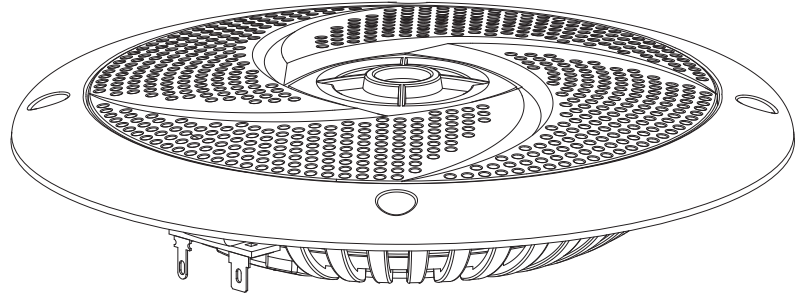


PYLE

PyleUSA.com

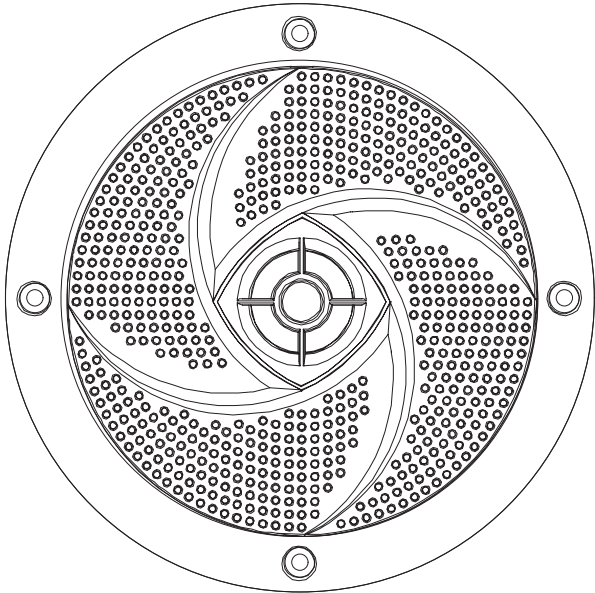

Model: PLMRS4W - PLMRS4B

4" -inch Speaker Pairs

Model: PLMRS43WL - PLMRS43BL

4" -inch Speaker Pairs with Built-in LED Lights

Model: PLMRS5W - PLMRS5B

5.25" -inch Speaker Pairs

Model: PLMRS53WL - PLMRS53BL

5.25" -inch Speaker Pairs with Built-in LED Lights

Model: PLMRS6W - PLMRS6B

6.5" -inch Speaker Pairs

Model: PLMRS63WL - PLMRS63BL

6.5" -inch Speaker Pairs with Built-in LED Lights

LOW-PROFILE MARINE SPEAKER SYSTEM

User Manual

These speakers were designed and manufactured for your installation needs and have been thoroughly tested to ensure consistent and reliable performance.

For further information, installation assistance or product troubleshooting visit us on PyleUSA.com

Speakers & Options:

Model Number	Speaker Size	Max Output Power	LED Light Bulb	Cut-Out Diameter	Mounting Depth
PLMRS4W	4"	100 Watt		3.7"	0.9"
PLMRS4B	4"	100 Watt		3.7"	0.9"
PLMRS43WL	4"	100 Watt	Blue Illumination	3.7"	0.9"
PLMRS43BL	4"	100 Watt	Blue Illumination	3.7"	0.9"
PLMRS5W	5.25"	180 Watt		4.7"	0.9"
PLMRS5B	5.25"	180 Watt		4.7"	0.9"
PLMRS53WL	5.25"	180 Watt	Blue Illumination	4.7"	0.9"
PLMRS53BL	5.25"	180 Watt	Blue Illumination	4.7"	0.9"
PLMRS6W	6.5"	240 Watt		5.3"	0.92"
PLMRS6B	6.5"	240 Watt		5.3"	0.92"
PLMRS63WL	6.5"	240 Watt	Blue Illumination	5.3"	0.92"
PLMRS63BL	6.5"	240 Watt	Blue Illumination	5.3"	0.92"

Model Number	Total Speaker Diameter	Total Speaker Depth	Magnet	Frequency Response	Speaker Weight
PLMRS4W	5.2" -inches	1.5" -inches	3.4 Oz	90Hz-18khz	0.66 lbs.(Each)
PLMRS4B	5.2" -inches	1.5" -inches	3.4 Oz	90Hz-18khz	0.66 lbs.(Each)
PLMRS43WL	5.2" -inches	1.5" -inches	3.4 Oz	90Hz-18khz	0.66 lbs.(Each)
PLMRS43BL	5.2" -inches	1.5" -inches	3.4 Oz	90Hz-18khz	0.66 lbs.(Each)
PLMRS5W	6.4" - inches	1.6" - inches	5.4 Oz	80Hz-18khz	0.88 lbs.(Each)
PLMRS5B	6.4" - inches	1.6" - inches	5.4 Oz	80Hz-18khz	0.88 lbs.(Each)
PLMRS53WL	6.4" - inches	1.6" - inches	5.4 Oz	80Hz-18khz	0.88 lbs.(Each)
PLMRS53BL	6.4" - inches	1.6" - inches	5.4 Oz	80Hz-18khz	0.88 lbs.(Each)
PLMRS6W	7.3" - inches	1.6" - inches	5.4 Oz	60Hz-18khz	0.95 lbs.(Each)
PLMRS6B	7.3" - inches	1.6" - inches	5.4 Oz	60Hz-18khz	0.95 lbs.(Each)
PLMRS63WL	7.3" - inches	1.6" - inches	5.4 Oz	60Hz-18khz	0.95 lbs.(Each)
PLMRS63BL	7.3" - inches	1.6" - inches	5.4 Oz	60Hz-18khz	0.95 lbs.(Each)

Features:

- Includes (2) Component Speakers
- Waterproof & Weather-Resistant Design
- Rugged Marine Grade Construction
- Low-Profile Slim Style Speaker Housing
- 2-Way Full Range Stereo Sound Reproduction
- Molded ABS Machined Basket and Grill
- Universal Standard OEM Replacement Size
- For Boat, Marine Watercraft & Off-Road Vehicles

What's in the Box:


- (2) Marine Speakers
- (2) Speaker Connection Wires, 9.8' ft.

Technical Specs:

- Voice Coil Type: Aluminum
- Construction Material: Engineered ABS
- Impedance: 4 Ohm

Speaker Wiring


Models: PLMRS4W - PLMRS4B
PLMRS5W - PLMRS5B
PLMRS6W - PLMRS6B
Speaker Pairs

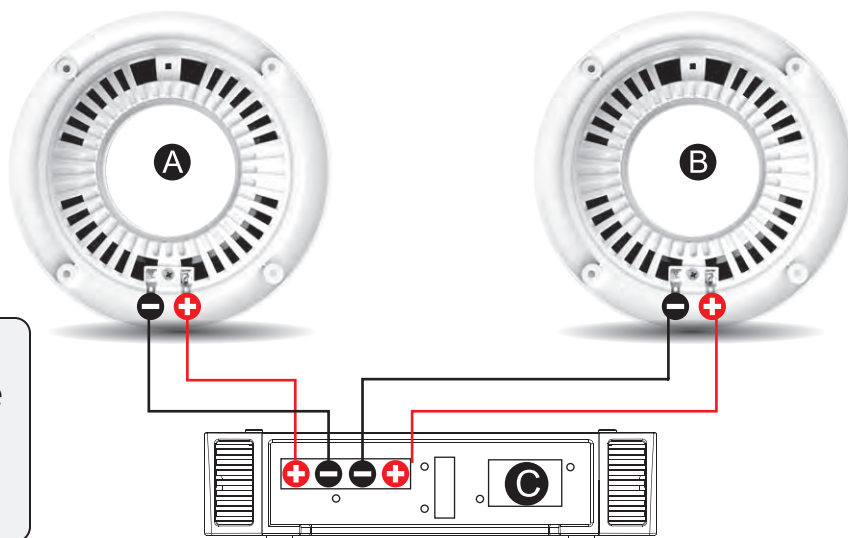

- Connect the red and black cables to their respective positive and negative terminals.
- Speakers 'A' and 'B' connect to an amplifier source 'C'

Speaker Wiring

Models: PLMRS43WL - PLMRS43BL
PLMRS53WL - PLMRS53BL
PLMRS63WL - PLMRS63BL
Speaker Pairs Built-in LED Lights

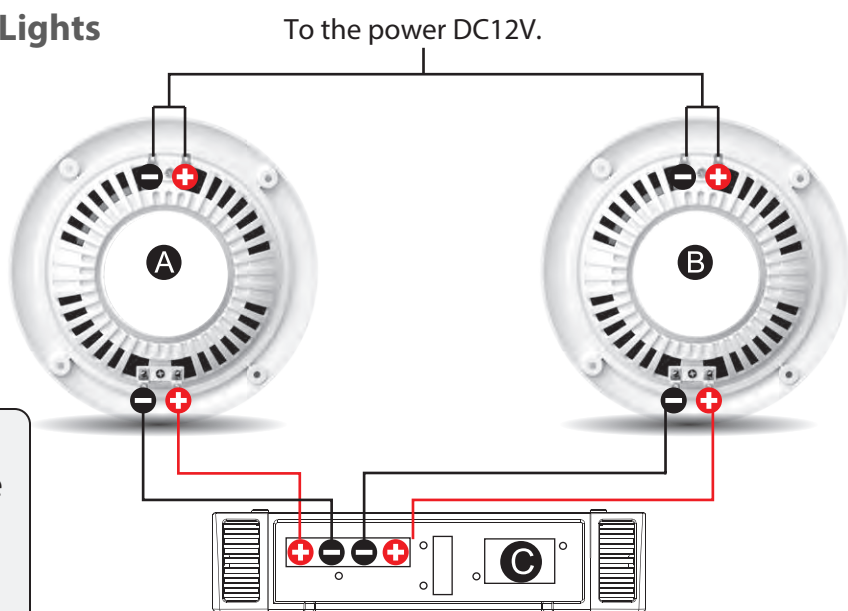

- Connect the red and black cables to their respective positive and negative terminals.
- Speakers 'A' and 'B' connect to an amplifier source 'C'

PYLE

PyleUSA.com



VISIT US ONLINE:

Have a question?

Need service or repair?

Want to leave a comment?

PyleUSA.com/ContactUs

PYLE