

Commander® Exposed Shower

FEATURES:

- Brass body construction
- 1/2" NPTM chrome plated brass riser supply lines
- Reversible valve body
- Vandal-resistant cross handles with color-coded indexes
- 1/4 turn ceramic cartridges to ensure drip-free performance
- Exposed chrome plated shower body assembly, on 6" centers
- Included shower head: S-2272-E175 with a 1.75 GPM (6.6 L/min) flow rate
- Polished chrome plated brass gooseneck with supporting strap

SHOWER OPTIONS:

- LH: Less shower head
- LSP: Less supply pipes


VALVE STANDARDS:

- ASME A112.18.1/CSA B125.1 certified
- WaterSense certified (S-2272-E175 showerhead)

WARRANTY:

Visit www.speakman.com for full product warranty information

- 5 Year Limited Warranty (commercial)
- 5 Year Limited Warranty (residential)

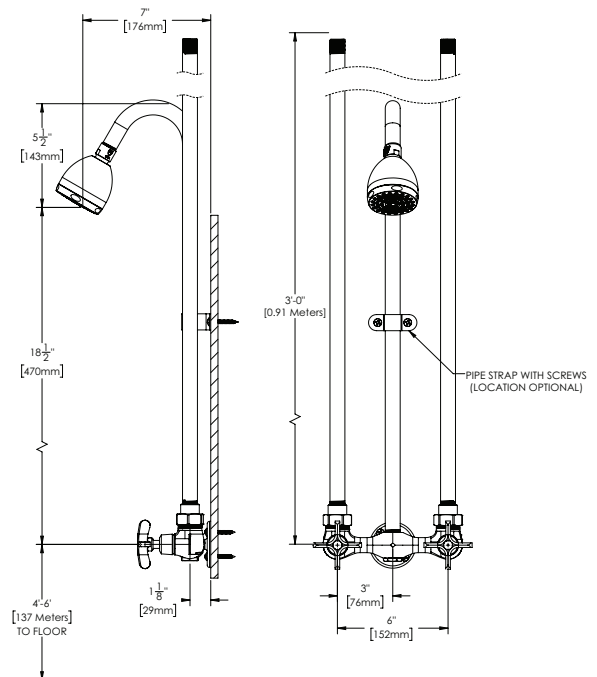

All dimensions are in inches (millimeters) unless otherwise specified and are subject to change without notice.

Architect/Engineer Approval Space:

P: 800-537-2107
 F: 800-977-2747
 W: WWW.SPEAKMAN.COM
 R: 01-SEPTEMBER 2022