

## Gooseneck AC Sensor Faucet w/ Manual Override

### MODELS:

- SF-9207: Gooseneck AC Sensor Faucet
- SF-9207-TMV: Gooseneck AC Sensor Faucet w/ Thermostatic Mixing Valve

### FEATURES:

- Brass construction with polished chrome finish
- Sensor eye at base of faucet
- Plug-in AC powered (plug included)
- Gooseneck spout
- Manual override
- 60 second flow time out feature
- 9/16"-24 UNF supply connection, supply lines not included
- Vandal-resistant 0.5 GPM (1.89 L/min) flow control

### OPTION:

- TMV: Thermostatic Mixing Valve (A-TMV)

### ADD-ONS:

- A-SF-GBLFE: alternate flow aerator group (1.5 GPM, 1.5 GPM laminar and 1.2 GPM)
- A-EA12: 13/16-27 1.2 GPM Aerator
- A-ELF: 13/16-27 1.2 GPM Laminar Flow Aerator
- A-UCM: Under Counter Mixer & Mounting Hardware
- A-HTS - Sensorflo HTS Flex Hoses Kit

### STANDARDS:

- ASME A112.18.1/CSA B125.1 certified
- NSF/ANSI 61 certified
- NSF/ANSI 372 certified
- ADA compliant

### WARRANTY:

Visit [www.speakman.com](http://www.speakman.com) for full product warranty information

- Limited Lifetime Warranty (residential)
- 5 Year Limited Warranty (commercial)




Information continues on next page

All dimensions are in inches (millimeters) unless otherwise specified and are subject to change without notice.

Architect/Engineer Approval Space:

P: 800-537-2107  
 F: 800-977-2747  
 W: WWW.SPEAKMAN.COM  
 R: 04-NOVEMBER 2021

## Gooseneck AC Sensor Faucet w/ Manual Override

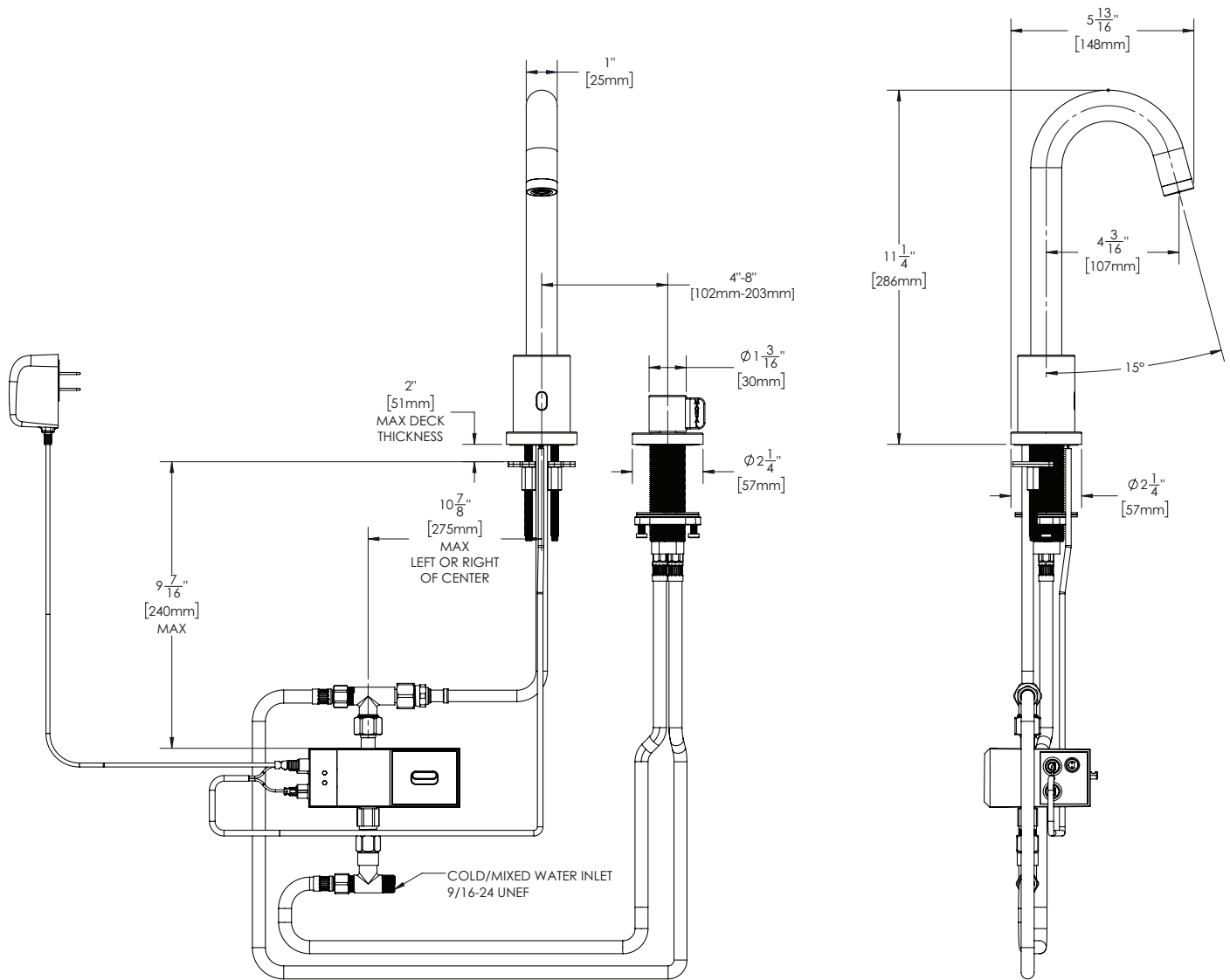

All dimensions are in inches (millimeters) unless otherwise specified and are subject to change without notice.

Architect/Engineer Approval Space:

P: 800-537-2107  
 F: 800-977-2747  
 W: WWW.SPEAKMAN.COM  
 R: 04-NOVEMBER 2021