



Meritor®

33" top-mount/undermount double-bowl kitchen sink

28197-1

Features

- 36" (914 mm) minimum base cabinet width
- Double-equal bowls
- 9" (229 mm) depth provides generous workspace
- Rounded corners are easy to clean
- Angled edge allows for easy sweeping of food or water from countertop to bowl
- SilentShield® sound-absorption technology offers quieter performance
- Single faucet hole
- Box includes: Sink, installation hardware
- Optional K-6401 sink rack (sold separately)

Material

- Sink constructed from premium 18-gauge stainless steel

Installation

- Top-mount or undermount

Recommended Products/Accessories

K-23729 Stainless steel cleaner

Optional Products/Accessories

- K-8799 Sink drain and strainer basket
- K-8801 Sink drain and strainer with tailpiece
- K-11352 Disposal Flange with Stopper




Codes/Standards

ASME A112.19.3/CSA B45.4

STERLING® One-Year Limited Warranty

See website for detailed warranty information.

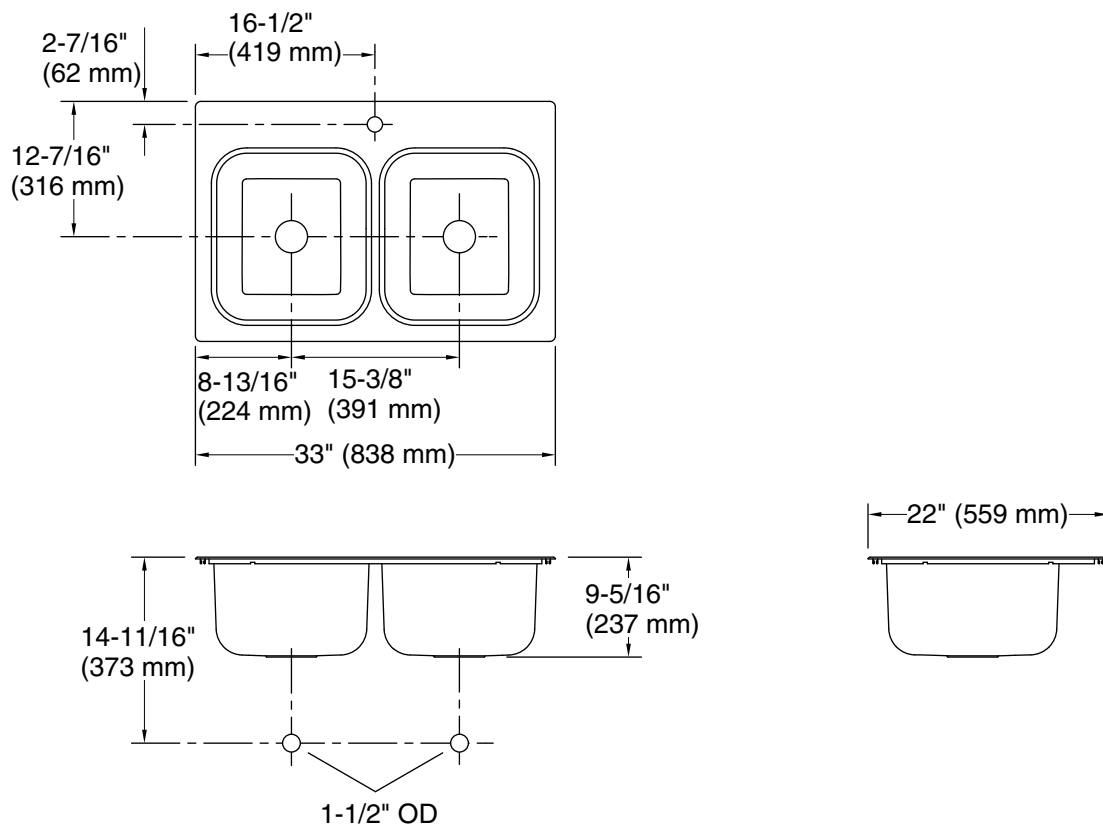

Technical Information

All product dimensions are nominal.

Bowl configuration:	Double equal
Installation:	Top-mount, Undermount
Min. base cabinet width:	36" (914 mm)
Bowl area (Left):	Length: 14-1/8" (359 mm) Width: 15-3/4" (400 mm) Bowl depth: 9" (229 mm)
Bowl area (Right):	Length: 14-1/8" (359 mm) Width: 15-3/4" (400 mm) Bowl depth: 9" (229 mm)
Number of deck holes:	1
Faucet hole(s):	1-7/16" (37 mm)
Drain hole:	3-3/4" (94 mm)
Template:	Top-mount/Undermount, 1476435-7, required, included

Notes

Install this product according to the installation instructions.