

KOHLER®

Top-mount/undermount large/medium bowl kitchen sink

Verse™
K-75791-1

Features

- 36" minimum base cabinet width.
- Large/medium bowls.
- 9" (229 mm) depth provides generous workspace.
- Single faucet hole.
- Includes installation hardware.

Material

- Premium 18-gauge stainless steel.

Installation

- Top-mount or undermount.

Recommended Products/Accessories

- K-3129 Sink rack for Undertone® and Verse™ kitchen sinks
- K-8801 Sink drain and strainer with tailpiece
- K-8799 Sink drain and strainer basket
- K-3132 Sink rack for Undertone® and Verse™ kitchen sinks
- K-23726 Drain treatment
- K-23729 Stainless steel cleaner

Optional Products/Accessories

- K-11352 Disposal Flange with Stopper



Codes/Standards

ASME A112.19.3/CSA B45.4

Lifetime Limited Warranty for KOHLER® Stainless Steel Sinks


See website for detailed warranty information.

1-800-4KOHLER (1-800-456-4537)

Kohler Co. reserves the right to make revisions without notice to product specifications.

For the most current Specification Sheet, go to www.kohler.com.

THE BOLD LOOK
OF **KOHLER®**

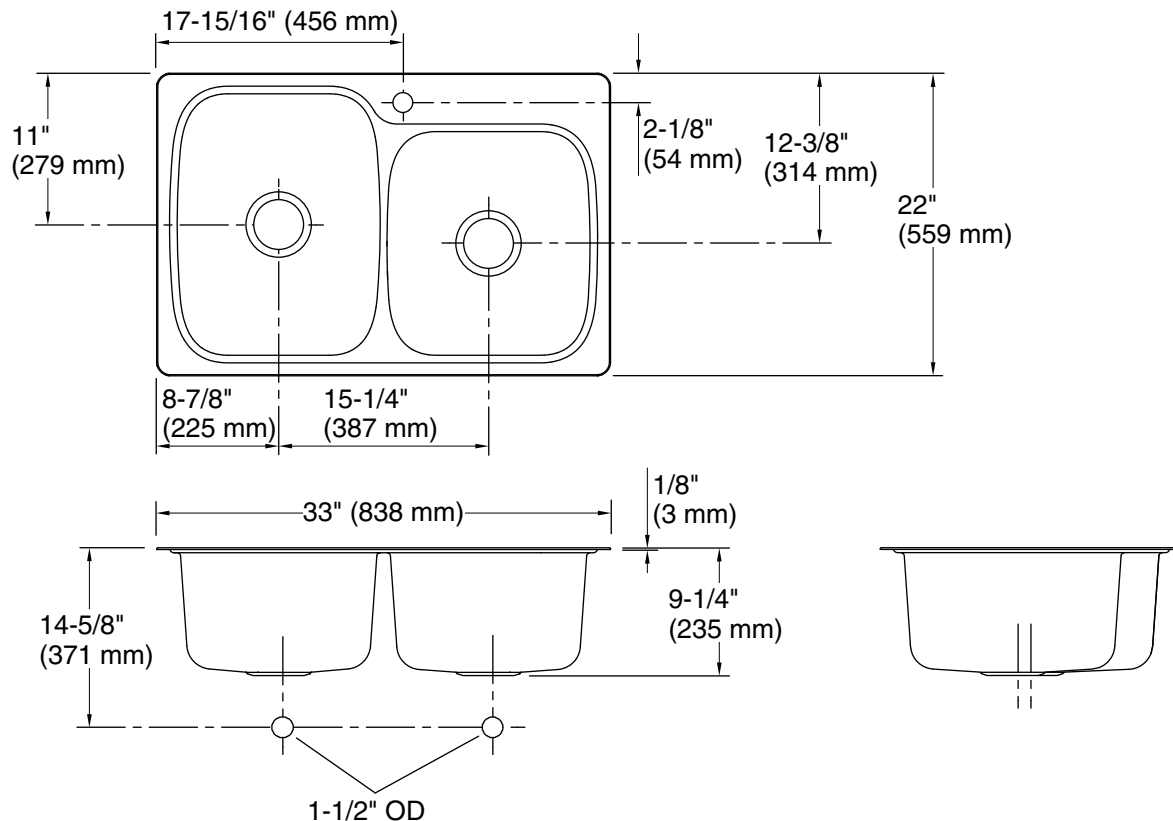

Technical Information

All product dimensions are nominal.

Installation:	Top-mount, Under-mount
Min. base cabinet width:	36" (914 mm)
Bowl area (Right):	Length: 14-3/16" (360 mm) Width: 15-11/16" (398 mm) Bowl depth: 9" (229 mm) Water depth: 9" (229 mm)
Bowl area (Left):	Length: 14-3/16" (360 mm) Width: 18-7/16" (468 mm) Bowl depth: 9" (229 mm) Water depth: 9" (229 mm)
Number of deck holes:	1
Faucet hole(s):	1-7/16" (37 mm)
Drain hole:	3-3/4" (94 mm)
Template:	1263722-7, required, included

Notes

Install this product according to the installation instructions.