

## DESCRIPTION

- Metal construction with various finishes identified by suffix
- With side spray
- Duralock™ Quick Connect Installation
- 1/2" IPS connection

## OPERATION

- Lever style handle
- Hot side counterclockwise to open (clockwise to close), cold side clockwise to open (counterclockwise to close)
- Will operate with less than 5 lbs. of force


## FLOW

- Aerator is limited to 1.5 gpm max (5.7 L/min)

## CARTRIDGE


- 1224 cartridge design
- Engineered polymers, non-ferrous and stainless steel materials

## STANDARDS

- Third party certified to ASME A112.18.1/CSA B-125.1 and all applicable requirements referenced therein
- Certified to NSF 61/9 & 372
- Meets CalGreen and Georgia SB370 requirements
- Complies with California Proposition 65 and with the Federal Safe Drinking Water Act
- ADA  for lever handles

## WARRANTY


- Lifetime limited warranty against leaks, drips and finish defects to the original homeowner
  - 10 year limited warranty when used in a multifamily installation
  - 5 year limited warranty when used in a commercial installation
- Visit [www.moen.com/support](http://www.moen.com/support) for complete details and limitations

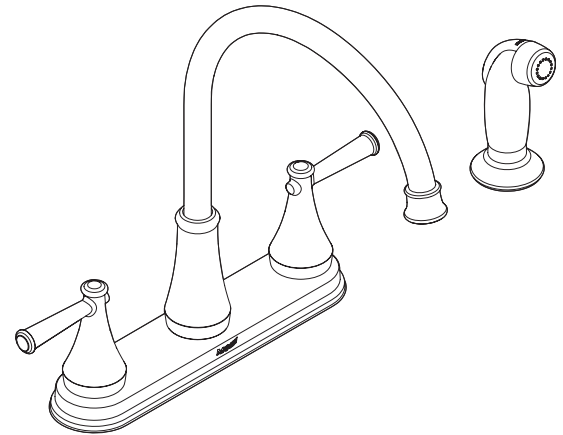

**Stevie™**  
**Two-Handle Lever Kitchen Faucet**  
**with Side Spray**

**Models:** 87292 series

**NOTE:** THIS FAUCET IS DESIGNED TO BE  
INSTALLED THROUGH 4 HOLES 1" MIN. DIA.

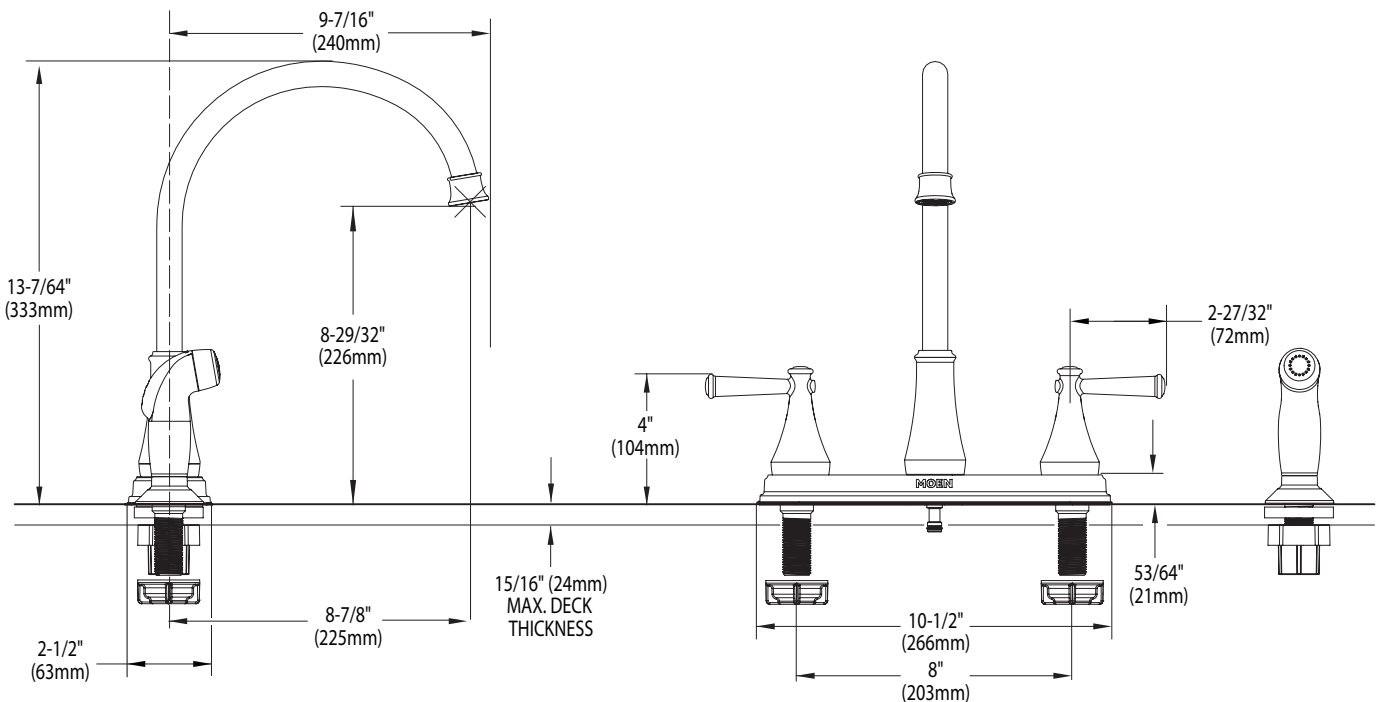

## CRITICAL DIMENSIONS

(DO NOT SCALE)