

## DESCRIPTION

- Reflex™ pulldown system offers smooth operation, easy movement and secure docking
- Metal construction with spot resist stainless finish
- Duralock® quick connect installation
- PowerClean Spray
- Flexible supply lines with 3/8" CC fittings connect directly to supply stop
- High arc spout provides height and reach to fill or clean large pots while pull out wand provides the maneuverability for cleaning or rinsing
- 360° rotating spout

## OPERATION

- Lever style handle
- Temperature controlled by 100° arc of handle travel
- Operates with less than 5 lbs. of force
- Operates in stream or spray mode in the pulldown or retracted position

## FLOW

- Flow is limited to 1.5 gpm (5.7 L/min) at 60 psi
- Power Boost™ Button activates boosted stream and boosted spray

## CARTRIDGE

- 1255™ Duralast™ cartridge for Single-Handle Faucets


## STANDARDS

- Third party certified to IAPMO Green, ASME A112.18.1/CSA B125.1 and all applicable requirements referenced therein including NSF 61/9 & 372
- Meets CalGreen and Georgia SB370 requirements
- Complies with California Proposition 65 and with the Federal Safe Drinking Water Act
- The backflow protection system in the device consists of two independently operating check valves, a primary and a secondary which prevent backflow

- ADA ♿ for lever handle

## WARRANTY

- Lifetime limited warranty against leaks, drips and finish defects to the original homeowner
  - 10 year limited warranty when used in a multifamily installation
  - 5 year limited warranty when used in a commercial installation
- Visit [www.moen.com/support](http://www.moen.com/support) for complete details and limitations

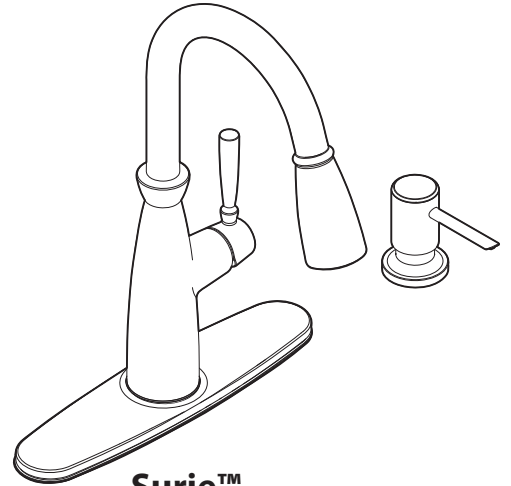

**Surie™**  
**Single Handle**  
**Pulldown Kitchen Faucet**  
**Model: 87395SRS**

**NOTE:** THIS FAUCET IS DESIGNED TO BE INSTALLED THROUGH 1, 2, 3 and 4 HOLE, 1-1/2" (38mm) MIN. DIA. (1 HOLE FOR SOAP DISPENSER)

