




see what Delta can do™

LOW FLOW AERATORS

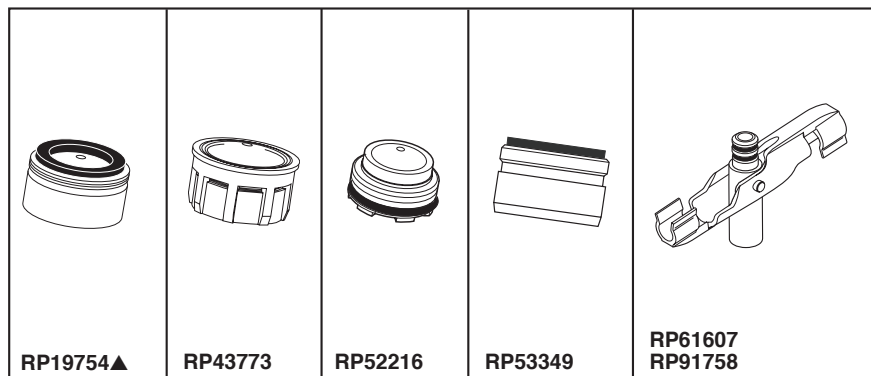

Submitted Model No.: _____

Specific Features: _____

STANDARD SPECIFICATIONS:

- Max. 1.5 gpm @ 60 psi, 5.7 L/min @ 414 kPa
- Max. 1.0 gpm @ 60 psi, 3.8 L/min @ 414 kPa

Part #	Description	Models	Finishes
RP19754▲	1.5 gpm aerator assy 15/16"-27 male	100/300/400 (DST & non-DST models) 2100/2400 140/340/440 (DST & non-DST models) 172/174 2176/2476 2274/2276 185	Chrome SS RB
RP53349	1.5 gpm jr. aerator assy 13/16"-27 male	190/2190 2170/2171/2172	Chrome
RP52216	1.5 gpm aerator insert	119/319/419 (DST & non-DST models) 155/156 (DST models) 4380	N/A
RP43773	1.5 gpm aerator insert	155/156 (non-DST models) 100/300/400 (DST & non-DST models) 2100/2400 140/340/440 (DST & non-DST models) 172/174 2176/2476 2274/2276 185 2457	N/A
RP61607	1.5 gpm adapter	Compatible with all DST pull-down or pull-out models	N/A
RP91758	1.0 gpm adapter	Compatible with all DST pull-down or pull-out models	N/A

WARRANTY

- Lifetime limited warranty on parts (other than electronic parts and batteries) and finishes: or, for commercial users, for 5 years from date of purchase.
- 5 year limited warranty on electronic parts (other than batteries); or, for commercial users, for 1 year from the date of purchase. No warranty is provided on batteries.

COMPLIES WITH:

- ASME A112.18.1 / CSA B125.1

▲ Designate Proper Finish Suffix