

### Features

- Single-function oblong rainhead features Full Coverage with Katalyst technology, a drenching spray experience ideal for rinsing shampoo from hair.
- MasterClean™ sprayface features an easy-to-clean surface that withstands mineral buildup.
- Optimized sprayface for maximum performance.
- 2.5 gpm (9.5 lpm) maximum flow rate at 80 psi (5.5 bar).

### Material

- Premium material construction for durability and reliability.
- KOHLER finishes resist corrosion and tarnishing.

### Technology

- Katalyst® air-induction technology infuses water with air, creating bigger drops for a more powerful spray.

### Installation

- 1/2 -14 NPT connection.
- Requires single-function rainhead shower arm and flange (sold separately).

### Recommended Products/Accessories

- K-23723 Faucet cleaner
- K-26319 3" ceiling-mount rainhead arm and flange
- K-26320 6" ceiling-mount rainhead arm
- K-26321 12" ceiling-mount rainhead arm and flange
- K-26322 16" wall-mount rainhead arm and flange
- K-26307 19" wall-mount rainhead arm and flange



### Codes/Standards





ASME A112.18.1/CSA B125.1  
DOE - Energy Policy Act 1992


### KOHLER® Faucet Lifetime Limited Warranty

See website for detailed warranty information.

### Available Colors/Finishes

*Color tiles intended for reference only.*

Color	Code	Description
	CP	Polished Chrome
	BN	Vibrant® Brushed Nickel
	BL	Matte Black
	2MB	Vibrant® Brushed Moderne Brass

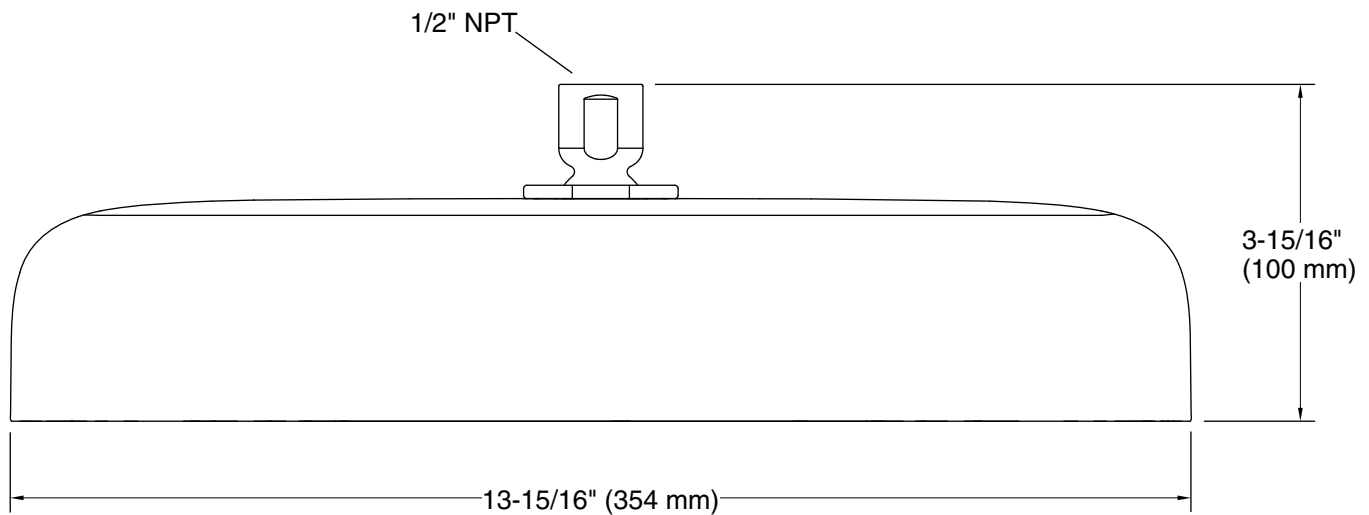

**Technical Information**

All product dimensions are nominal.

**Showerhead/Body Spray:**

Rated maximum flow: 2.5 gal/min (9.5 l/min)

Pressure: 80 psi (5.5 bar)

**Notes**

For use with automatic compensating valves rated at 2 gal/min (7.6 l/min) or less.