

Features

- 5" (127 mm) gooseneck spout reach
- Gooseneck spout swivels for unobstructed use of the sink
- Two lever handles offer separate control of hot and cold water
- Aerated flow delivers a smooth, steady stream of water
- 1.5 gpm (5.7 lpm) maximum flow rate at 60 psi (4.14 bar)
- Quarter-turn washerless ceramic disc valves
- Less drain

Material

- Premium metal construction for durability and reliability
- KOHLER finishes resist corrosion and tarnishing

Installation

- For 4" (102 mm) centers
- Three-hole installation

Recommended Products/Accessories

K-23723 Faucet cleaner

Optional Products/Accessories

1012715



ADA **CSA B651**

Codes/Standards

ASME A112.18.1/CSA B125.1

NSF/ANSI/CAN 61

NSF/ANSI/CAN 372

All applicable US Federal and State material regulations

DOE - Energy Policy Act 1992

California Energy Commission (CEC)


ADA

ICC/ANSI A117.1

CSA B651

KOHLER[®] Faucet Lifetime Limited Warranty

See website for detailed warranty information.

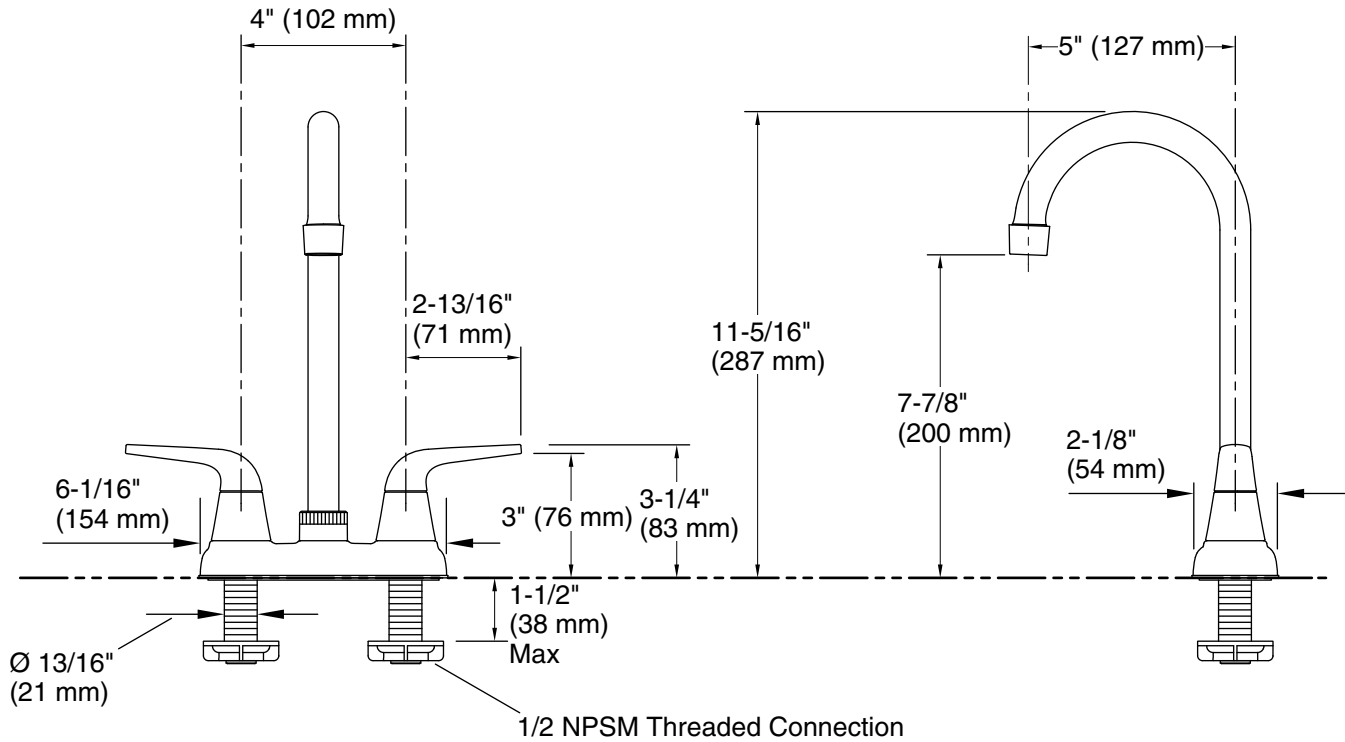

Technical Information

All product dimensions are nominal.

Drain included: No

Spout:

Spout reach: 5" (127 mm)

Notes

Install this product according to the installation instructions.

ADA, CSA B651 compliant when installed to the specific requirements of these regulations.