

## Features

- Flush-to-wall design (recommended) provides a clean aesthetic; can also be installed within shower floor interior
- Extend channel length from 36" to 60" for easier specification and precise wall-to-wall installation (if desired)
- Channel is pitched to outlet for easy cleaning and complete drainage; handles up to 15 gpm (56.8 lpm) flow capacity (rate may vary by installation)
- Drain outlet location can be adjusted to bypass joints, venting, or other in-floor obstacles
- Outlet adapter can be preattached to drain pipe for simplified installation and access to couplings
- Easy-clean domed hair strainer prevents clogs
- Subfloor brackets are height-adjustable to ensure the drain channel is mounted at the correct height during installation
- Removeable tile guide/mud guard keeps channel clean of debris during installation and provides a straight edge to tile against
- Wide-top flange with protective film ensures excellent waterproof adhesion
- Can also be installed with KOHLER side-outlet adapter K-28987 (sold separately)
- Requires Kohler 1¼" x 36", 1¼" x 48", or 1¼" x 60" linear drain grate

## Material

- Solid stainless steel and brass construction
- KOHLER finishes resist corrosion and tarnishing

## Installation

- Through-the-floor, installed with tile





## Codes/Standards

None Applicable

## KOHLER® One-Year Limited Warranty

See website for detailed warranty information.

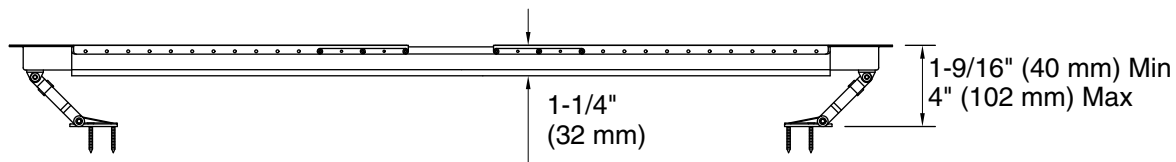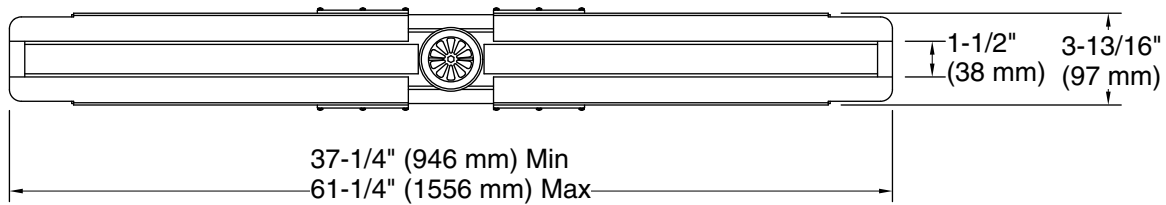

## Technical Information

All product dimensions are nominal.

Installation Type: In-floor

Material: Stainless Steel, Plastic, Brass

Height: 1-1/2" (38 mm) - 4" (102 mm)