

Features

- Rigid, precision-machined perforated grate pattern offers best-in-class drain aesthetic
- Easily field-trimmable to fit any showering space
- Lightweight yet durable grate insert is easy to handle during installation and throughout product life
- Thread-in, rubber-capped grate feet offer secure placement within drain channel
- Feet are height-adjustable up to one inch and easily accessible through the top of grate for a faster, more precise installation
- Requires K-80646 Kohler 2-1/2" linear drain channel

Material

- Anodized aluminum construction
- KOHLER finishes resist corrosion and tarnishing

Installation

- Field trimmable to accommodate customize size and installation


Required Products/Accessories

K-80646 2½" x 36"-60" linear drain channel

Included Components

Additional Components:

- End caps
- Mounting feet
- Stainless steel lift key

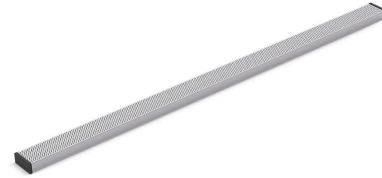

Codes/Standards

ASME A112.18.2/CSA B125.2




KOHLER® One-Year Limited Warranty

See website for detailed warranty information.

Available Colors/Finishes

Color tiles intended for reference only.

| Color | Code | Description |
|---|------|--------------------------------|
|  | SH | Bright Silver |
|  | BL | Matte Black |
|  | 2MB | Vibrant® Brushed Moderne Brass |
|  | BNK | Anodized Brushed Nickel |

 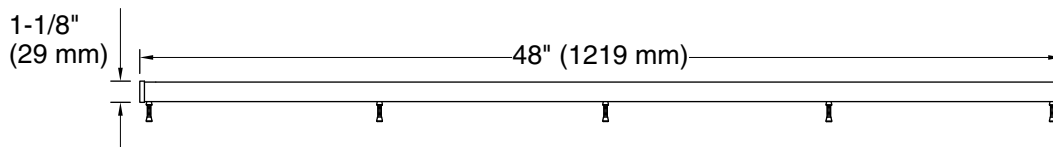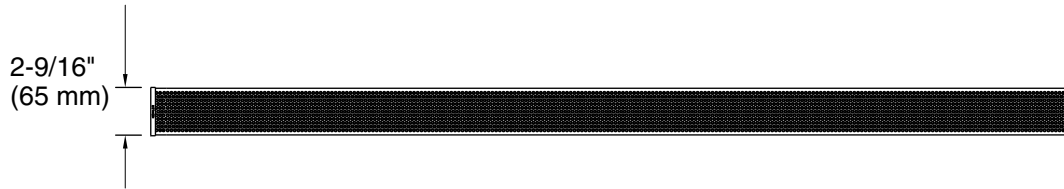

Technical Information

All product dimensions are nominal.

Installation Type: Flush-mount

Material: Anodized Aluminum, Stainless Steel,
Plastic

Height: 1-3/16" (30 mm) - 2-3/16" (56 mm)