



## Pneumatic conversion kit for in-wall tank **K-8108**

### Features

- For use with the K-18829 2" x 4" in-wall tank and carrier system.

### Required Products/Accessories

For wall-mount installation

K-18829 2x4 In-Wall Tank & Carrier System

### Recommended Products/Accessories

K-23251-F Flush actuator plate

K-23252-F Dual-flush actuator plate



### Codes/Standards

ASME A112.19.5/CSA B45.15

### **KOHLER® One-Year Limited Warranty**

See website for detailed warranty information.




1-800-4KOHLER (1-800-456-4537)

Kohler Co. reserves the right to make revisions without notice to product specifications.

For the most current Specification Sheet, go to [www.kohler.com](http://www.kohler.com).

5-29-2021 22:37 - US/CA

THE BOLD LOOK  
OF **KOHLER®**

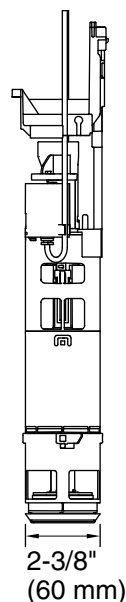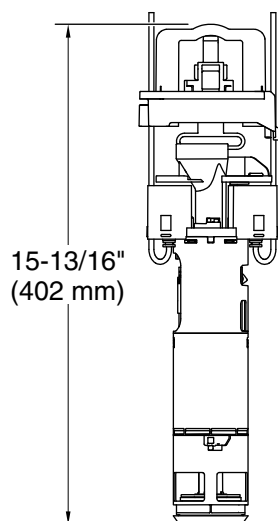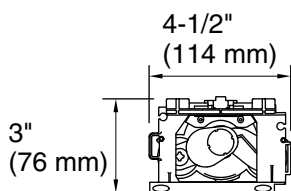

### Technical Information

All product dimensions are nominal.

Toilet type: In-wall tank, In-wall mount

Waste Outlet: Wall

Flush type: Gravity washdown

#### Water Consumption

Full: 1.6 gpf (6 lpf)

Reduced: 0.8 gpf (3 lpf)

### Fixture Supply Requirements

Max static pressure: 80 psi (551.6 kPa)

### Notes

Install this product according to the installation instructions.