


▲ Designate proper finish suffix

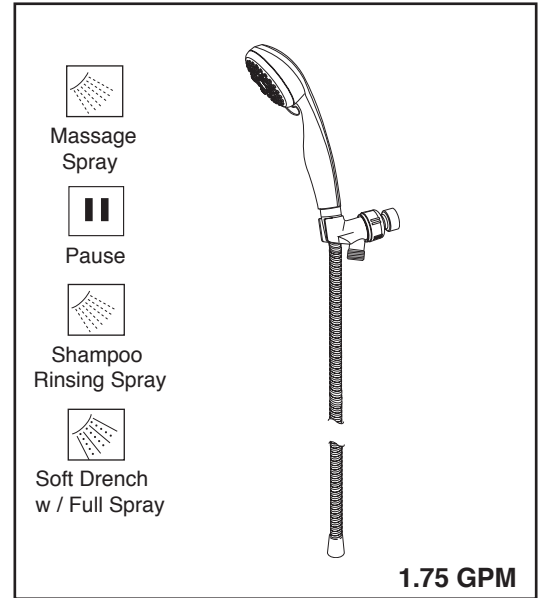

## HAND SHOWER

- 4-Spray Setting Handshower
- Touch-Clean® nozzles

### STANDARD SPECIFICATIONS:

- Max flow rate 1.75 gpm @ 80 psi, 6.6 L/min @ 550 kPa
- Hand held shower with four spray patterns – pause is a non-positive shut-off
- 60" (1524 mm) reinforced vinyl hose
- Model includes shower arm mount
- Adjustable shower arm mount allows for hands-free showering
- Easy-turn spray dial

### WARRANTY

- Parts and Finish - Lifetime limited warranty; or for commercial purchasers, 10 years for multi-family residential (apartments and condominiums) and 5 years for all other commercial uses, in each case from the date of purchase.



### COMPLIES WITH

- ASME A1 12.18.1 / CSA B125.1
- EPA WaterSense®