



PEERLESS®

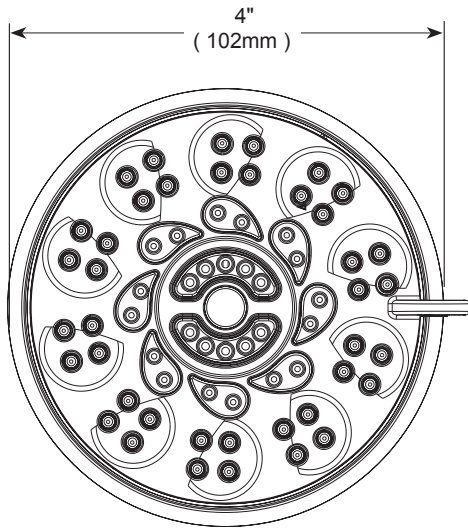

76610▲
76610D▲

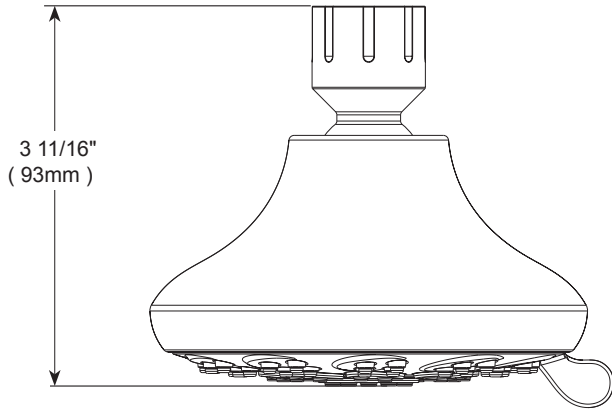

Full Body
Spray



Shampoo
Rinse Spray



Massage
Spray




Shampoo Rinse
w/ Full Spray



Full Spray
w/ Massage



Pause

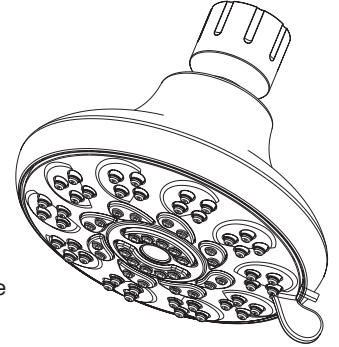

SHOWERHEAD

■ 6-Spray Setting Showerhead

FEATURES:

- Touch-Clean® Nozzles

STANDARD SPECIFICATIONS:

- Maximum flow rate 1.75 gpm @ 80 psi, 6.6 L/min @ 550 kPa (76610▲ only)
- Maximum flow rate 2.5 gpm @ 80 psi, 9.5 L/min @ 550 kPa (76610D▲ only)
- ABS showerhead with six settings - not a positive shut-off
- Standard 1/2" pipe fitting
- The ball swivel angle is 54° (27° per side)
- Easy-turn spray dial

WARRANTY

- Lifetime limited warranty on parts (other than electronic parts and batteries) and finishes; or, for commercial users, for 5 years from the date of purchase.
- 5 year limited warranty on electronic parts (other than batteries); or for commercial users, for 1 year from the date of purchase. No warranty is provided on batteries.



COMPLIES WITH

- ASME A112.18.1 / CSA B125.1
- EPA WaterSense® (76610▲ only)

▲ Designate proper finish suffix