


# PEERLESS®

P299685LF▲  
P299685LF-▲-W  
P299685LF-▲-ECO-W

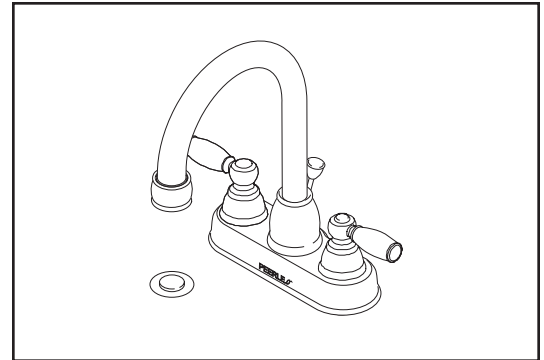

## BATHROOM FAUCET

- Two Handle Centerset Deck Mount
- 4 Inch 3 Hole Sink Applications

### STANDARD SPECIFICATIONS:

- Max flow rate: 1.2 gpm @ 60 psi, 4.5 L/min @ 414 kPa
- Three hole mount
- Hot and cold stems are interchangeable
- 1/4 turn handle stops
- Control mechanism is a rotating cylinder type with stainless steel plate and 90° rotation, with replaceable non-metallic seats
- Models have drain with pop-up type fitting with plated flange and stopper
- RP76691 thick deck mounting kit adds 1 1/4" (32 mm) to maximum deck thickness



### WARRANTY:

- Parts and Finish - Lifetime limited warranty; or for commercial purchasers, 10 years for multi-family residential (apartments and condominiums) and 5 years for all other commercial uses, in each case from the date of purchase.




### COMPLIES WITH:

- ASME A112.18.1 / CSA B125.1
- ASME A112.18.2 / CSA B125.2
- ♿ Indicates compliance to ICC/ANSI A117.1- Valve control only
- EPA WaterSense®

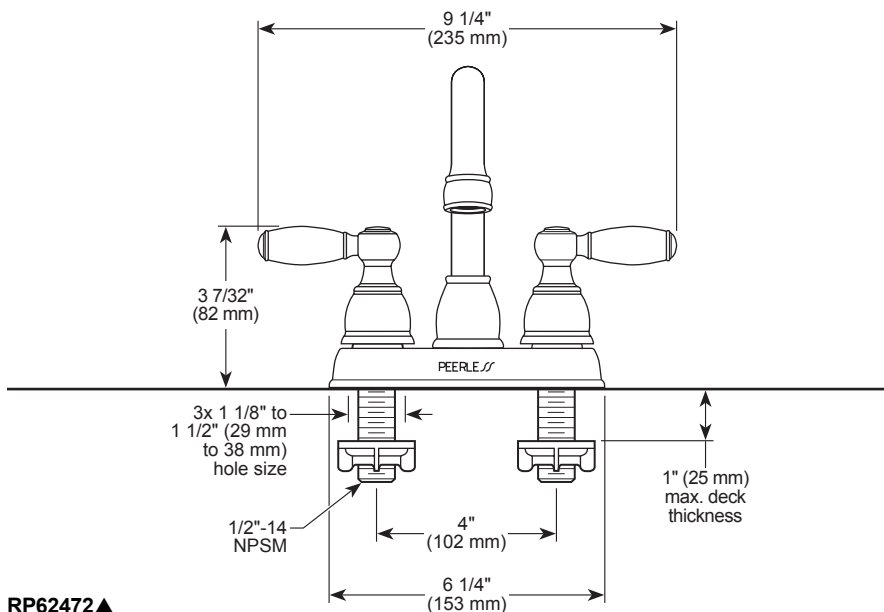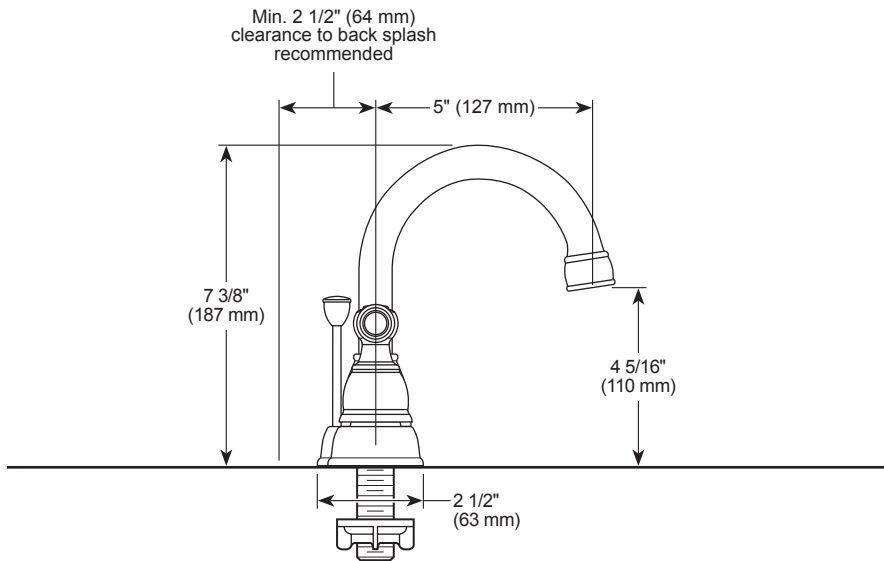

### RP62472▲ Plastic Pop-Up

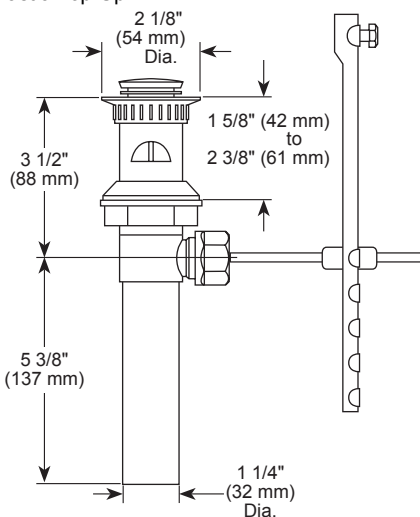

▲ Designate proper finish suffix