



Undertone®

23" undermount single-bowl kitchen sink
K-3325

Features

- 27" (686 mm) minimum base cabinet width
- Single bowl
- 9-1/2" (241 mm) depth provides generous workspace
- Rear drain placement increases cabinet storage space underneath sink
- Includes installation hardware
- Sink drain with strainer sold separately

Material

- Premium 18-gauge stainless steel

Installation

- Undermount

Recommended Products/Accessories

- K-6391 Sink rack for Undertone® sinks
- K-3192 Sink rack for Iron/Tones® kitchen sinks
- K-23726 Drain treatment
- K-23729 Stainless steel cleaner

Optional Products/Accessories

- 7400 Stainless Steel Sink Drain and Strainer




Codes/Standards

ASME A112.19.3/CSA B45.4
IAPMO Certification

KOHLER® Stainless Steel Sinks Lifetime Limited Warranty

See website for detailed warranty information.

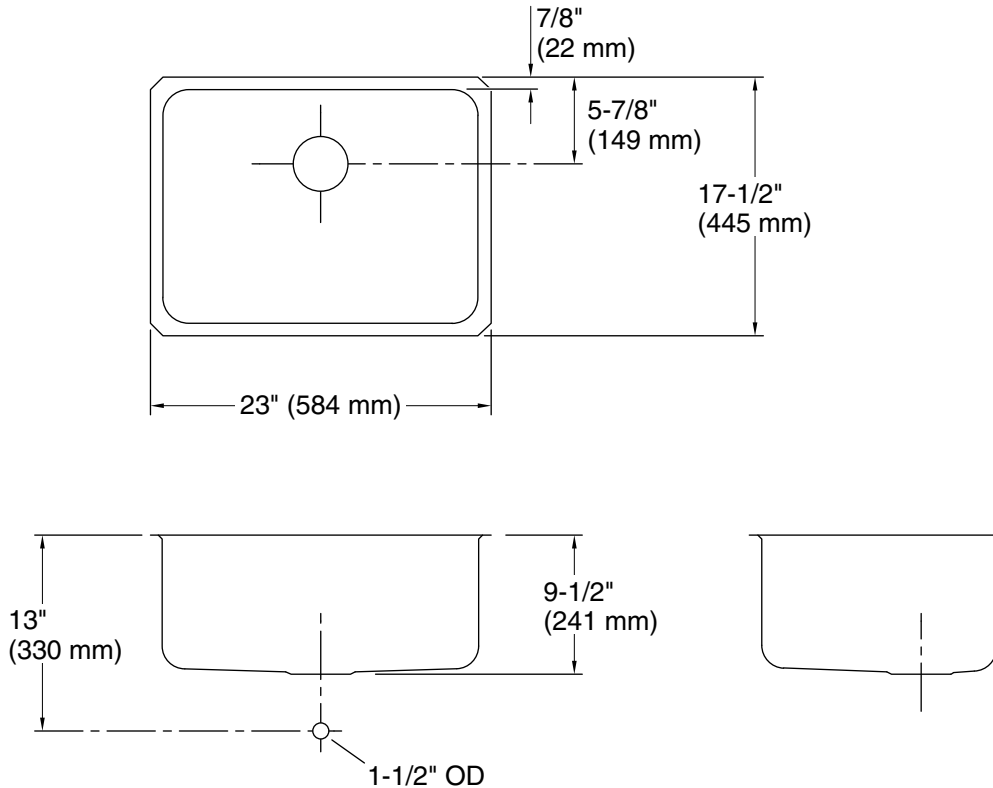

Technical Information

All product dimensions are nominal.

Bowl configuration: Single

Min. base cabinet width: 27" (686 mm)

Bowl area (Center): Length: 21-1/4" (540 mm)
Width: 15-3/4" (400 mm)
Bowl depth: 9-1/2" (241 mm)
Water depth: 9-1/2" (241 mm)

Template: Under-mount, 113193-7, required, included

Notes

Install this product according to the installation instructions.