

ProFlex™

Dryer Duct



- Ideal for both gas and electric dryer applications
- UL2158A listed and marked for safe dryer venting
- Constructed of heavy duty, fire resistant aluminum foil laminate that encapsulates a high density, corrosion resistant wire helix
- Will not support combustion

Product Code	UPC Code 060672	Size	Packaging	Pack Qty.	Pack Wt. (lbs)	Pack Cube (cu. ft.)
BTD45	600052	4" x 5'	Retail Box	18	16	1.44
BTD48	600106	4" x 8'	Retail Box	18	18	1.44
BTD48ZW	600106	4" x 8'	Retail Box / Cut Case	24	21	1.50
BTD48TC	600090	4" x 8' with tension clamps	Retail Box	18	18	1.44
BTD420ZW	600212	4" x 20'	Retail Box / Cut Case	10	21	2.37
TD425	600250	4" x 25'	Standard Box	1	3	0.44
TD450	600304	4" x 50'	Standard Box	1	6	0.60


Maximum Velocity: 5500 FPM

Temperature Range: -20°F to 285°F

Bending Radius: 1 x diameter

Note: Per UL 2158A only ducts 8' or less can be UL marked

AIR FRICTION LOSS IN STRAIGHT RUNS

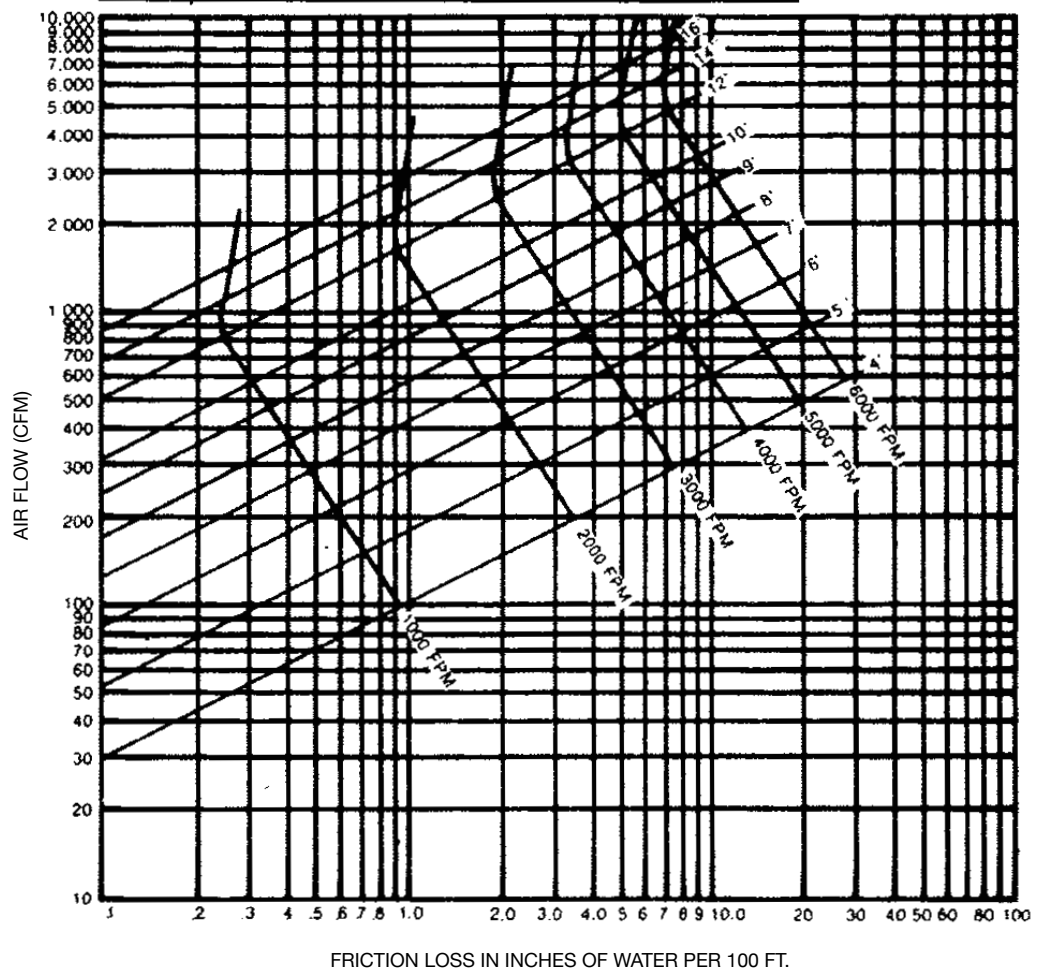

Scan this QR code to view helpful product feature and installation videos