


SPECIFICATIONS	
SCSC-400-2032	
1. MAXIMUM CAPACITY -	400 lbs
2. MINIMUM CAPACITY -	175 lbs.
3. MAXIMUM HEIGHT -	30 3/8 in.
4. MINIMUM HEIGHT -	13 3/4 in.
5. WEIGHT -	137 lbs.
6. TRAVEL -	16 5/8 in.
7. TABLE WIDTH -	19 3/4 in.
8. TABLE LENGTH -	32 1/4 in.
9. OVERALL HEIGHT -	30 1/2 in.
10. OVERALL WIDTH -	19 3/4 in.
11. OVERALL LENGTH -	40 in.

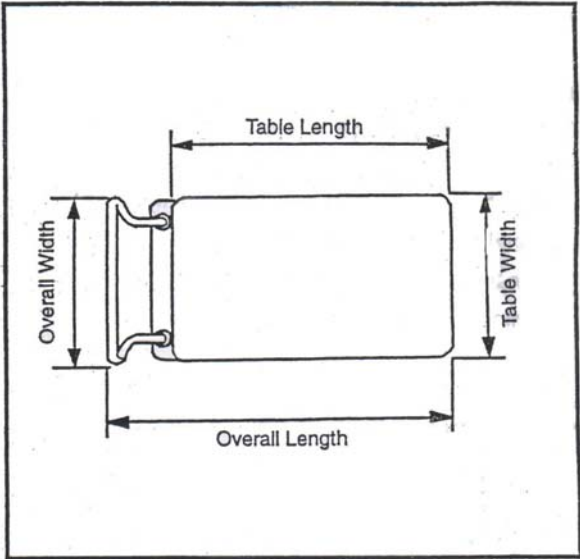

SPECIFICATIONS	
SCSC-800-2040	
1. MAXIMUM CAPACITY -	800 lbs
2. MINIMUM CAPACITY -	220 lbs.
3. MAXIMUM HEIGHT -	31 1/8 in.
4. MINIMUM HEIGHT -	14 1/2 in.
5. WEIGHT -	229 lbs.
6. TRAVEL -	16 5/8 in.
7. TABLE WIDTH -	20 1/2 in.
8. TABLE LENGTH -	39 3/4 in.
9. OVERALL HEIGHT -	35 1/2 in.
10. OVERALL WIDTH -	20 1/2 in.
11. OVERALL LENGTH -	48 1/2 in.

