


S-118-AA-FR (1,500 lbs Fully Powered Stacker with Powered fork reach & Adjustable Forks & Adjustable Legs)

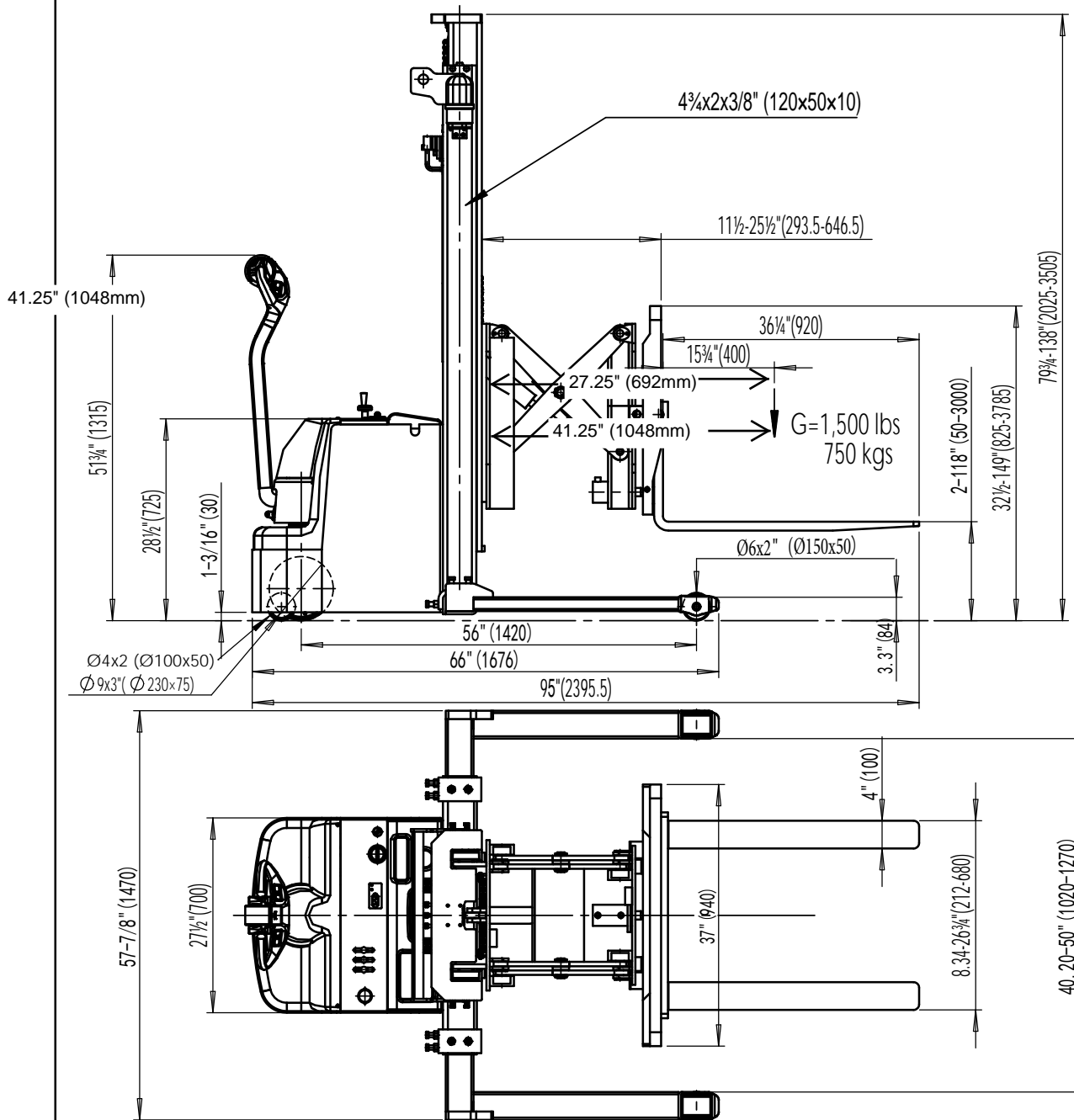

Specifications

Model # S-118-AA-FR
 Capacity (UDL) LC (27 1/4"): 1,500 lbs (0-62")
 Capacity (UDL) LC (27 1/4"): 1,000 lbs (62 - 118")
 Capacity (UDL) LC (41 1/4"): 800 lbs (0-62")
 Capacity (UDL) LC (41 1/4"): 600 lbs (62 - 118")
 Lift Height: 118"
 Lowered height: 2"
 Adjustable Forks & adjustable legs Overall mast height (Retracted): 79 3/4"
 Drive wheel: Ø9x3"
 Front wheel: Ø6x2"

Stabilizer wheel: Ø4x2.0"
 Drive Motor: DC24V/0.5Kw

Lift Motor: DC24V/2.0Kw
 Battery: 2x12V/80-95Ah
 Battery Charger: 24V/12amp
 Travel Speed w/load: 3.1m/h
 Travel Speed w/o load: 3.8m/h

VESTIL MANUFACTURING CORP.	
Model #:	S - 118 - AA - FR
Descrip:	Powered Drive, Powered Lift and Powered Reach Stacker
Design:	T.M
Date:	03/19/16