
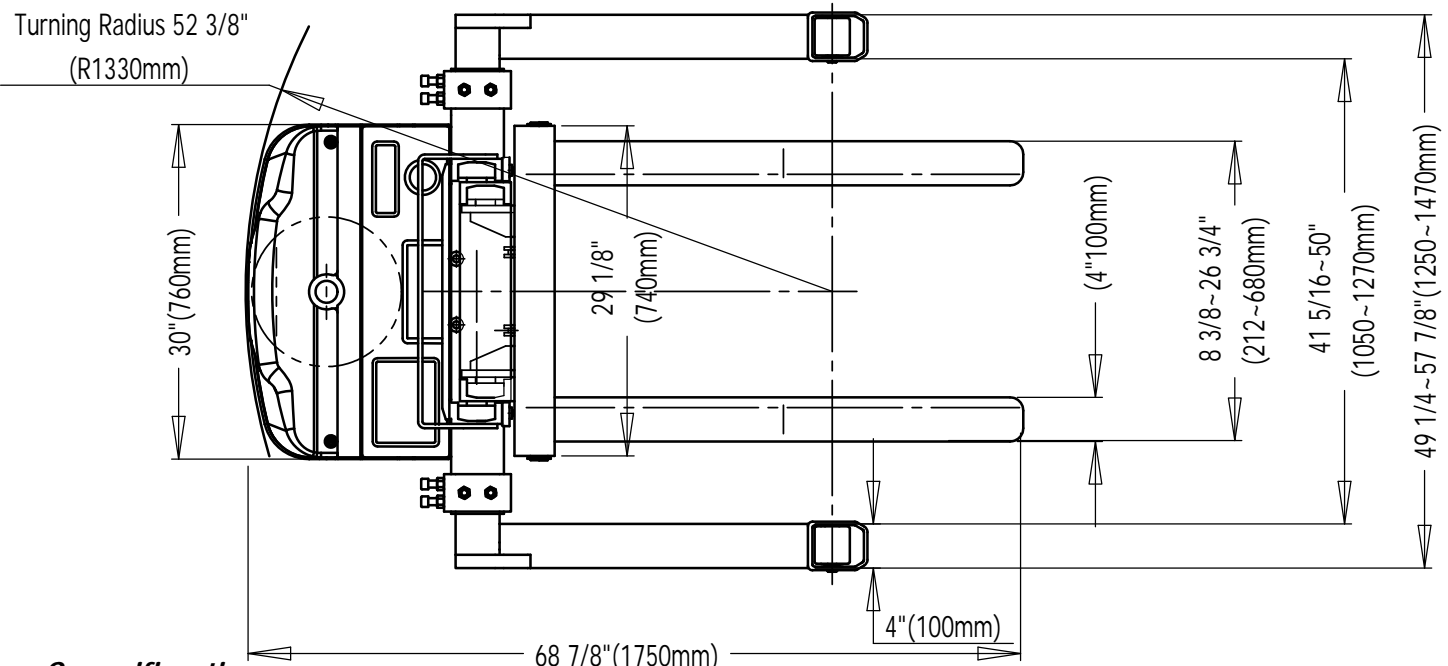


S - 150 - AA (FULLY POWERED STACKER-ADJUSTABLE FORKS & ADJUSTABLE LEGS)

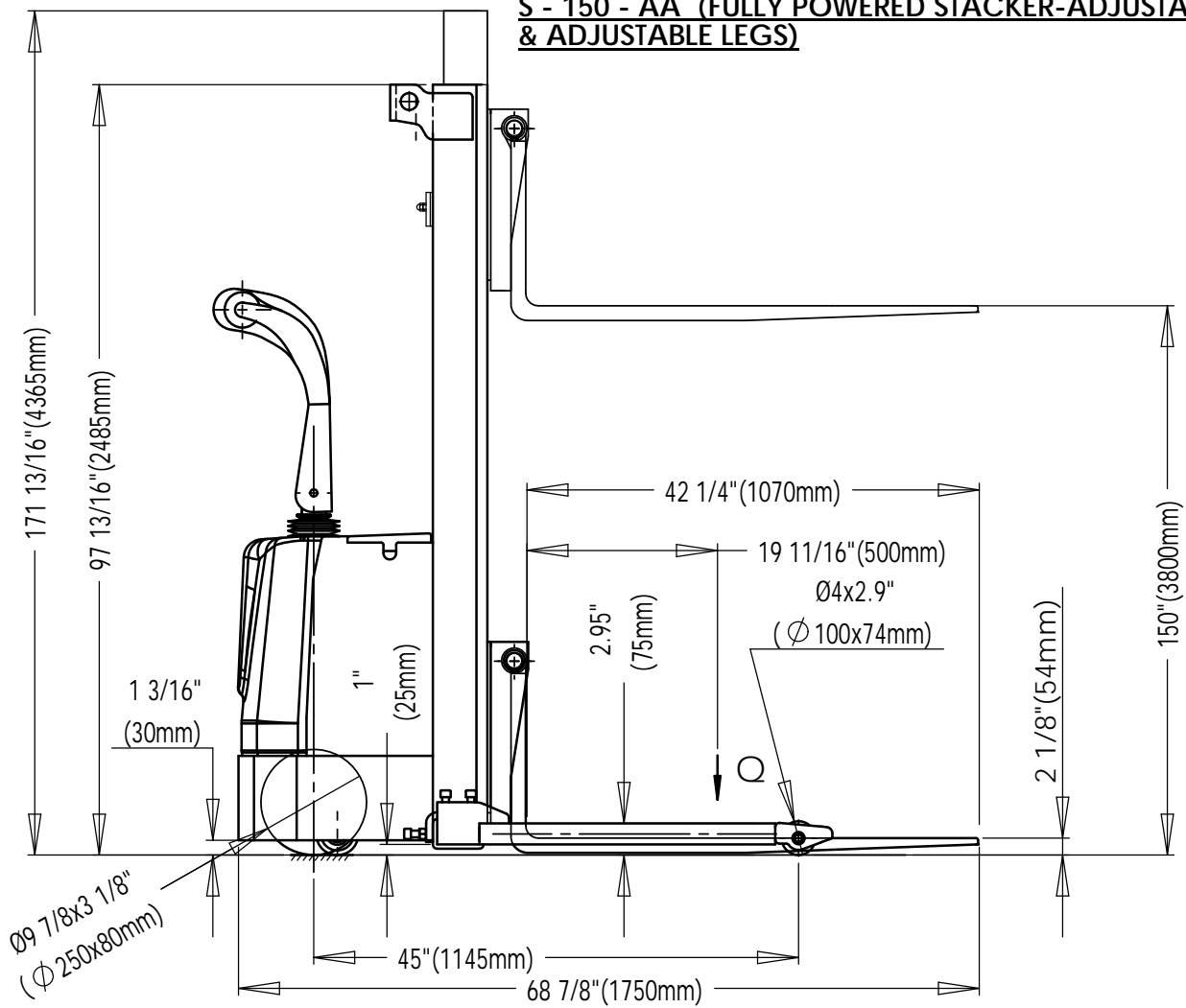

Specifications

Model # S-150-AA
 Capacity (UDL): 2,000 lbs. up to 62"
 Capacity (UDL): 1,500 lbs. 62" to 118"
 Capacity (UDL): 1,000 lbs. 118" to 137"
 Capacity (UDL): 750 lbs. 137" to 150"
 Lift height: 118"
 Lowered height: 2 1/8"
 Adjustable Forks & adjustable legs
 Mast: Single

Safety Shield: Yes
 Overall mast height: 171 13/16"
 Drive wheel: Ø9 7/8 x 3 1/8"
 Front wheel: Ø4x 2.9"
 Stabilizer wheel: Ø3x1 7/16"
 Handle: CH-2
 Drive Motor: DC24V/0.7Kw
 Lift Motor: DC24V/2.0Kw
 Travel Speed w/load: 2.30m/h
 Travel Speed w/o load: 2.5m/h
 Battery: 2x12V/95Ah

VESTIL MANUFACTURING CORP.		DRWG./FILE NAME:
DRAWN BY: TM	DATE: 09/18/10	S-150-AA
Reference:		