

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0039013023](#)  
**Status:** **Active**  
**Overview:** Mini-Fit Family Power Connectors  
**Description:** Mini-Fit Jr. Plug Housing, Dual Row, 2 Circuits, UL 94V-2, without Panel Mounting Ears, Natural

**Documents:**

<a href="#">Drawing (PDF)</a>	<a href="#">Application Specification AS-5557-001-001 (PDF)</a>
<a href="#">3D Model</a>	<a href="#">Packaging Specification PK-5559-002-001 (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">Test Summary 55560010-TS-000 (PDF)</a>
<a href="#">Product Specification PS-45750-001-001 (PDF)</a>	<a href="#">Test Summary TS-5556-002-001 (PDF)</a>
<a href="#">Product Specification PS-5556-001-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Application Specification 55560001-AS-000 (PDF)</a>	

**Agency Certification**

CSA	LR19980
UL	E29179

**General**

Product Family	Crimp Housings
Series	5559
Application	Power, Wire-to-Board, Wire-to-Wire
Comments	Current = 13A max. per circuit when header is mated to a receptacle loaded with 45750 series terminals crimped to 16 AWG wire. See Molex product specification PS-45750-001 for additional current derating information.
Overview	<a href="#">Mini-Fit Family Power Connectors</a>
Product Name	Mini-Fit Jr.
Taxonomy	Connector Housings
UPC	800753617926

**Physical**


Breakaway	No
Circuits (maximum)	2
Color - Resin	Natural
Flammability	94V-2
Gender	Plug
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	0.857/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	4.20mm
Pitch - Termination Interface	4.20mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

**Electrical**

Current - Maximum per Contact	13.0A
-------------------------------	-------

**Solder Process Data**

Lead-freeProcess Capability	N/A
-----------------------------	-----

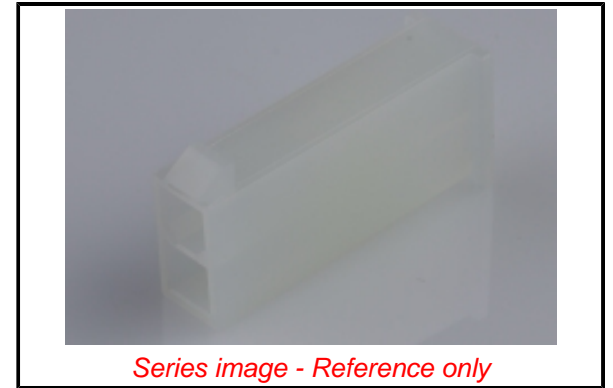

Series image - Reference only

**EU ELV**

**Compliant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Compliant

Not Contained

**Search Parts in this Series**

[5559 Series](#)

**Mates With**

Mini-Fit Jr. Receptacle Housing [39013028](#), [39012025](#) <br>Mini-Fit Jr. TPA Cable Assembly [45135](#) <br>Mini-Fit Jr. Cable Assembly [245135](#)

**Use With**

Mini-Fit Male Crimp Terminals [5558](#) <br>Mini-Fit Plus HCS Crimp Terminals [46012](#) <br>Mini-Fit Jr. Grounding Pin [30490](#) <br>Mini-Fit Pre-Crimped Leads [797580005](#), [797580013](#) <br>Mini-Fit Jr. Backshell [204723](#)

**Material Info**

Engineering Number 5559-02P1

**Reference - Drawing Numbers**

Application Specification 55560001-AS-000, AS-5557-001-001  
Packaging Specification PK-5559-002-001  
Product Specification PS-45750-001-001, PS-5556-001-001  
Sales Drawing 55590001-SD-000  
Test Summary 55560010-TS-000, TS-5556-002-001

This document was generated on 10/19/2022

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**