


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0040130853](#)  
**Status:** **Active**  
**Description:** MiniFit Term Crp Male Bs Au

**Documents:**

<a href="#">Drawing (PDF)</a>	<a href="#">Application Specification 55560001-AS-000 (PDF)</a>
<a href="#">Product Specification 55560002-PS-CH-000 (PDF)</a>	<a href="#">Packaging Specification 55580001-PK-000 (PDF)</a>
<a href="#">Product Specification 55560002-PS-ES-000 (PDF)</a>	<a href="#">Test Summary 55560010-TS-000 (PDF)</a>
<a href="#">Product Specification 55560002-PS-SK-000 (PDF)</a>	<a href="#">Test Summary TS-5556-002-001 (PDF)</a>
<a href="#">Product Specification PS-5556-001-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification PS-5556-002-001 (PDF)</a>	

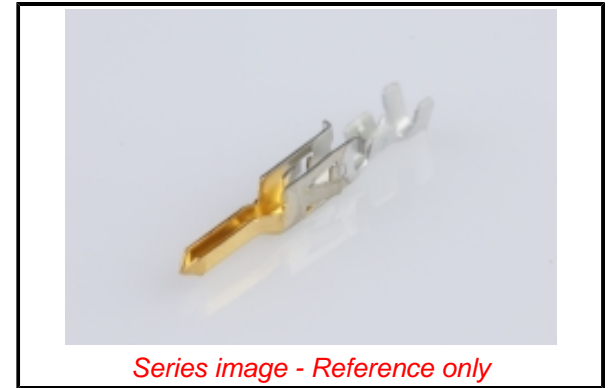

**General**

Product Family	Crimp Terminals
Series	<a href="#">5558</a>
Crimp Quality Equipment	Yes
Taxonomy	Crimp Terminals
UPC	800753839915

**Physical**

Net Weight	1.000/g
------------	---------

**Material Info**

Engineering Number	5558GS7
--------------------	---------

**Reference - Drawing Numbers**

Application Specification	55560001-AS-000
Packaging Specification	55580001-PK-000
Product Specification	55560002-PS-CH-000, 55560002-PS-ES-000, 55560002-PS-SK-000, PS-5556-001-001, PS-5556-002-001
Sales Drawing	SD-5558-002-001
Test Summary	55560010-TS-000, TS-5556-002-001

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2022)4187-DC (10  
June 2022)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[5558](#) Series

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

**Description**

**Product #**

Extraction Tool for Mini-Fit Jr. Terminals	<a href="#">11030044</a>
FineAdjust Applicator for Mini-Fit Double Crimp Applications Using Two 22 AWG Wires	<a href="#">2037026300</a>
PremiumGrade Hand Crimp Tool for Mini-Fit Jr. Male and Female Terminals, 18-24 AWG	<a href="#">638190901</a>
FineAdjust Applicator for 18-20	<a href="#">639015600</a>

AWG and 18-24  
 AWG Wires with  
 Insulation Diameter  
 1.90-2.30mm  
 FineAdjust Applicator [639023900](#)  
 for Insulation OD  
 1.40-1.70mm - 18-24  
 AWG  
 FineAdjust Applicator [639024800](#)  
 for Insulation OD  
 2.50-2.95mm  
 Optimized for 18  
 AWG Only  
 FineAdjust Applicator [639024900](#)  
 for Insulation OD  
 2.30-2.60mm - 18-24  
 AWG  
 FineAdjust Applicator [639047800](#)  
 for Insulation OD  
 2.50-2.95mm, 18-24  
 AWG  
 FineAdjust Applicator [639048000](#)  
 for Insulation OD  
 1.65-2.05mm, 18-24  
 AWG  
 T2 Terminator [639115600](#)  
 for insulation OD  
 1.90-2.30mm - 18-24  
 AWG  
 T2 Terminator [639123900](#)  
 for insulation OD  
 1.40-1.70mm - 18-24  
 AWG  
 T2 Terminator [639124800](#)  
 for insulation OD  
 2.50-2.95mm  
 optimized for 18  
 AWG only  
 T2 Terminator [639124900](#)  
 for insulation OD  
 2.30-2.60mm - 18-24  
 AWG  
 T2 Terminator [639147800](#)  
 for Mini-Fit Crimp  
 Terminals, 18-24  
 AWG with Large  
 Insulation ODs  
 T2 Terminator [639148000](#)  
 for Mini-Fit Crimp  
 Terminals, 18-24  
 AWG with Smaller  
 Insulation ODs

This document was generated on 10/19/2022

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**