

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0430610008](#)
Status: **Active**
Overview: SPOX Connector System
Description: 3.96mm Pitch SPOX Housing, 8 Circuits, Natural

Documents:

3D Model	3D Model (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	43061
Application	Power, Wire-to-Board
Comments	Glow Wire Equivalent Part Number 430613008
Overview	SPOX Connector System
Product Name	SPOX
Taxonomy	Connector Housings
UPC	800753576414

Physical

Breakaway	No
Circuits (maximum)	8
Circuits Detail	8
Color - Resin	Natural
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	2.637/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.96mm
Pitch - Termination Interface	3.96mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	0° to +75°C


Solder Process Data

Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Reference - Drawing Numbers

Sales Drawing	SD-43061-001, SD-43061-002
---------------	----------------------------

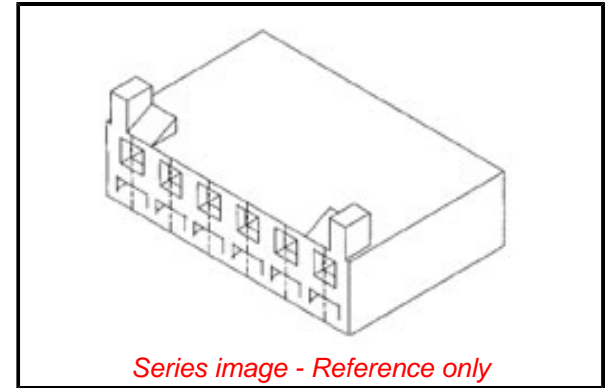

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[43061 Series](#)

Mates With

3.96mm Pitch KK or SPOX headers

Use With

SPOX Terminal [5194](#) , [5225](#)