

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0638137000](#)  
**Status:** **Active**  
**Overview:** [Application Tooling](#)  
**Description:** Extractor Tool for 2.80mm Crimp Terminals

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)


**General**

Product Family	Application Tooling
Series	<a href="#">207121</a>
Comments	See Tooling Specification (PDF) Above
Function	Extraction
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	<a href="mailto:applicationtooling@molex.com">applicationtooling@molex.com</a>
Overview	<a href="#">Application Tooling</a>
Product Name	N/A
Taxonomy	Crimp Presses and Crimp Hand T
Tool Type	Extraction Hand Tool
UPC	884982141445
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

**Material Info**

**Reference - Drawing Numbers**

Application Tooling Documents [ATS-638137000-001](#)

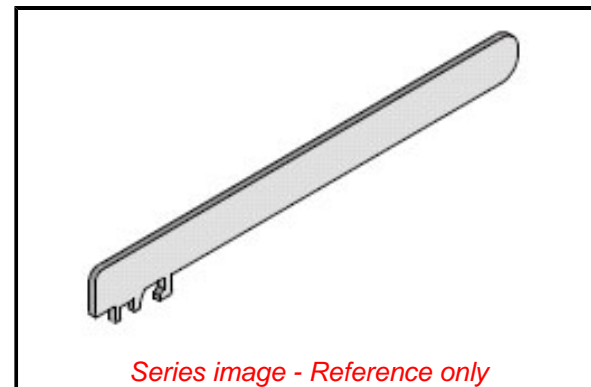

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[207121](#) Series

**Use With**

[98658](#) MOX Crimp Terminal, Female, 0.635mm Crimp Terminal in 2.54mm MOX Receptacle Housing with TPA Dual Row, 1x 6 Circuits.

**Application Tooling | [FAQ](#)**

Description	Product #
-------------	-----------

2.85mm Pitch MOX Receptacle Housing with TPA, Single Row, 6 Circuits, Black	<a href="#">981930001</a>
---	---------------------------

MOX Crimp Terminal, Female, 0.635mm, 20-24 AWG (0.22-0.60mm <sup>2</sup> ), Reel, Tin (Sn)	<a href="#">986581211</a>
--	---------------------------

MOX Crimp Terminal, Female, 0.635mm, 18-22 AWG (0.75mm <sup>2</sup> ), Reel, Tin (Sn)	<a href="#">986581212</a>
---	---------------------------

MOX Crimp Terminal, Female, 0.635mm, 18-22 AWG (0.75mm <sup>2</sup> ), Reel, Tin (Sn)	
---	--

MOX Crimp Terminal, Female, 0.635mm, 20-24 AWG (0.22-0.50mm <sup>2</sup> ), Reel, Tin (Sn)	<u>986581213</u>
MOX Crimp Terminal, Female, 0.635mm, 20-24 AWG (0.22-0.60mm <sup>2</sup> ), Reel, Selective Gold	<u>986581221</u>
MOX Crimp Terminal, Female, 0.635mm, 18-22 AWG (0.75mm <sup>2</sup> ), Reel, Selective Gold	<u>986581222</u>
MOX Crimp Terminal, Female, 0.635mm, 20-24 AWG (0.22-0.50mm <sup>2</sup> ), Reel, Selective Gold	<u>986581223</u>
MOX Crimp Terminal, Female, 0.635mm, 20-24 AWG (0.22-0.60mm <sup>2</sup> ), Reel, 2 Points Selective Gold	<u>986581231</u>
MOX Crimp Terminal, Female, 0.635mm, 18-22 AWG (0.75mm <sup>2</sup> ), Reel, 2 Points Selective Gold	<u>986581232</u>
MOX Crimp Terminal, Female, 0.635mm, 20-24 AWG (0.22-0.50mm <sup>2</sup> ), Reel, 2 Points Selective Gold	<u>986581233</u>

This document was generated on 10/11/2022

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**