

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0638233100](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: Hand Crimp Tool for Male Flat Blade Crimp Terminals

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Application Tooling
Series	207129
Comments	See Tooling Specification (PDF) Above; Type: 4A
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	PremiumGrade
Taxonomy	Crimp Presses and Crimp Hand T
Tool Type	Hand Crimp Tool
UPC	884982212701
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.


Physical

Net Weight 439.200/g

Material Info

Reference - Drawing Numbers

Application Tooling Documents
 ATS-6382331HM-001, TM-638000029-001, TM-638000029CN-001, TM-638000029DE-001, TM-638000029FR-001, TM-638000029IT-001, TM-638000029JP-001, TM-638000029KR-001, TM-638000029MY-001, TM-638000029PL-001, TM-638000029RU-001, TM-638000029SK-001, TM-638000029SP-001, TM-638000029TH-001, TM-638000029TW-001, TM-638000029VN-001

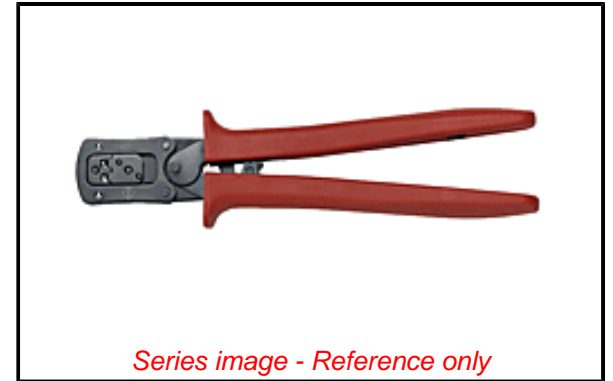

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/61/2018 (27 June 2018)

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[207129](#) Series

Use With

[43178](#) Sabre Male Flat Blade Crimp Terminals, (2) 18 AWG (UL1015), and (2) 20 AWG (UL1015) Wire Stacked Vertically

Application Tooling Description

FAQ Product #

Sabre Crimp Terminal, Male, 14-16 AWG or Double 18+20 AWG, 3.60mm Max. Insulation Diameter, Reel Packaged, Unplated, Brass Contact

[431782001](#)

Sabre Crimp Terminal, Male, 14-16 AWG or Double 18+20 AWG, 3.60mm Max. Insulation Diameter,

[431782002](#)

Reel Packaged, Tin
(Sn) Plated Brass
Contact

Sabre Crimp 431786002

Terminal, Male,

14-16 AWG or

Double 18+20

AWG, 3.60mm

Insulation Diameter,

Reel Packaged,

Tin (Sn) Plated

Brass Contact, Last-

Make Wipe Length,

Complies with

UL1977 Finger Proof

Access Requirement

This document was generated on 10/10/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION