

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0731160003](#)
Status: **Active**
Overview: RF Connectors, RF Cable Assemblies and RF Components
Description: MCRF-to-MCRF, 1.13mm Cable Diameter, Length 304.8mm, H18, 50 Ohms, Bag

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

| | |
|------------------------|--|
| Product Family | Cable Assemblies |
| Series | 73116 |
| Assembly Configuration | Dual Ended Connectors |
| Connector to Connector | MCRF-to-MCRF |
| Overview | RF Connectors, RF Cable Assemblies and RF Components |
| Product Name | MCRF, RF |
| Taxonomy | RF Cable Assemblies |
| Type | RF Cable Assembly |
| UPC | 884982813052 |

Physical

| | |
|---------------------------|-----------------|
| Cable Length | 304.80mm (1.0') |
| Circuits (Loaded) | 0 |
| Gender | Plug/Plug |
| Material - Metal | Phosphor Bronze |
| Material - Plating Mating | Gold |
| Material - Resin | Polyester |
| Number of Rows | 1 |
| Packaging Type | Bag |
| Single Ended | No |
| Wire/Cable Type | Coaxial |


Electrical

| | |
|-----------|-----|
| Impedance | 50Ω |
|-----------|-----|

Material Info

Reference - Drawing Numbers

| | |
|---------------|------------------|
| Sales Drawing | SD-73116-000-001 |
|---------------|------------------|

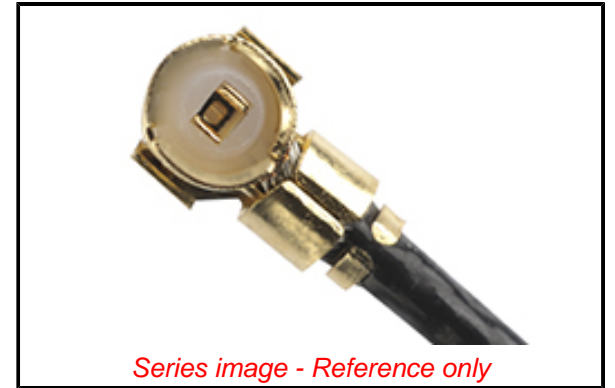

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[73116 Series](#)

Mates With

[734120110 MCRF, 50 Ohm, Receptacle](#)