

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0731160055](#)
Status: **Active**
Overview: RF Connectors, RF Cable Assemblies and RF Components
Description: MCRF-to-Pigtail, 1.37mm Cable Diameter, Length 152.4mm, H25, 50 Ohms, One Piece Per Bag

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	73116
Assembly Configuration	Single Ended Connector
Connector to Connector	MCRF-to-Pigtail
Overview	RF Connectors, RF Cable Assemblies and RF Components
Product Name	MCRF, RF
Taxonomy	RF Cable Assemblies
Type	RF Cable Assembly
UPC	884982813588

Physical

Cable Length	152.40mm (6.000")
Circuits (Loaded)	0
Gender	Plug-Pigtail
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Resin	Polyester
Net Weight	0.821/g
Number of Rows	1
Packaging Type	Bag
Single Ended	Yes
Wire/Cable Type	Coaxial


Electrical

Impedance	50Ω
-----------	-----

Material Info

Reference - Drawing Numbers

Sales Drawing	SD-73116-005-001
---------------	------------------

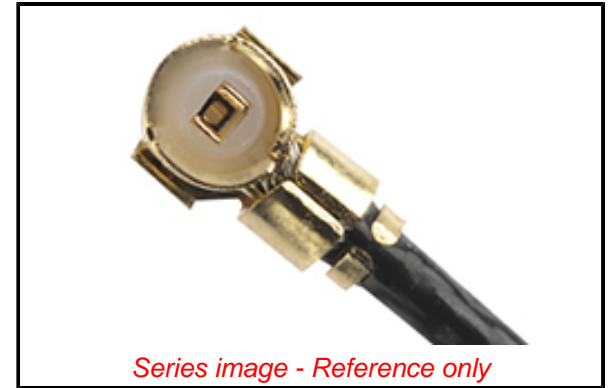

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[73116 Series](#)

Mates With

[734120110 MCRF, 50 Ohm, Receptacle](#)