

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0734036261](#)
Status: **Active**
Overview: [FAKRA PCB, Cable and Sealed Connection Systems](#)
Description: 50 Ohms, FAKRA SMB Plug, Straight, for RG-316 and RG-174 Cable, Keying Code B, Cream White

Documents:

[3D Model](#) [Application Specification AS-73597-045-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

General

Product Family [RF/Coax Connectors](#)
Series [73403](#)
Application [Automotive](#)
Overview [FAKRA PCB, Cable and Sealed Connection Systems](#)
Product Name [FAKRA, SMB](#)
Style [Cable](#)
Taxonomy [RF / Coaxial Connectors](#)
Type [Subminiature](#)
UPC [887191449562](#)
Wire/Cable Type [RG-174, RG-316](#)

Physical

Cable Attachment [N/A](#)
Gender [Plug](#)
Keying to Mating Part [Yes](#)
Net Weight [3.199/g](#)
Orientation [Straight](#)
PCB Mounting [N/A](#)
Packaging Type [Bag](#)
Panel Mount [No](#)
Panel Mount Method [N/A](#)
Reverse Polar [No](#)

Electrical

Frequency [6 GHz](#)
Impedance [50Ω](#)
Power / Voltage [VOLTAGE: 335 Vrms@Sea Level](#)


Solder Process Data

Duration at Max. Process Temperature (seconds) [010](#)
Lead-freeProcess Capability [SMC&WAVE](#)
Max. Cycles at Max. Process Temperature [002](#)
Process Temperature max. C [260](#)

Material Info

Reference - Drawing Numbers

Application Specification [AS-73597-045-001](#)
Sales Drawing [SD-73403-626-001](#)

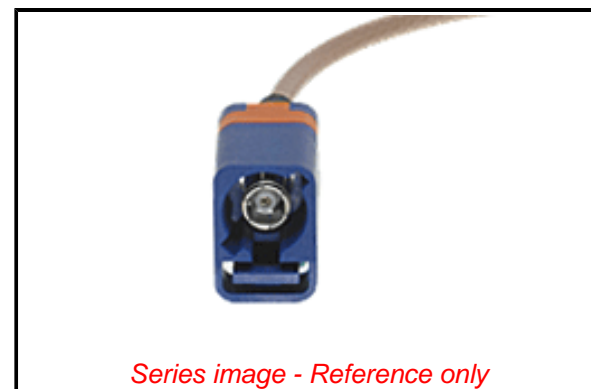

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per -
D(2020)9139-DC (19
Jan 2021)

Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[73403 Series](#)