

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010081](#)
Status: **Active**
Overview: GWconnect Heavy Duty Connectors (HDC)
Description: GWconnect Crimp Contact Insert, Female, 8-Pole, 10A, for Turned or Stamped Crimp Contacts, Size 3A «21x21»

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA 256883
 UL E249674

General

Product Family Industrial Connectors / Enclosures
 Series [93601](#)
 Component Size 3A «21x21»
 Component Type Inserts - Crimp Contact
 Insert Series S-D8
 Overview [GWconnect Heavy Duty Connectors \(HDC\)](#)
 Product Category Heavy Duty Connectors
 Product Name GWconnect
 Standard CSA C22.2 NO. 182.3, EN 60664-1, EN 61984, UL 1977
 Taxonomy Heavy-Duty Connectors
 UPC 887191868899

Physical


Durability (mating cycles max) 500
 Flammability UL 94V-0
 Gender Female
 Insert Color Grey
 Material - Insert Polycarbonate
 Net Weight 7.900/g
 Number of Rows 3
 Packaging Type Bag
 Polarized to Mating Part Yes
 Poles 8
 Temperature Range - Operating -40° to +125°C

Electrical

Current - Maximum per Contact 10.0A
 Voltage - Maximum 50V

Material Info

Engineering Number 7108.4002.0

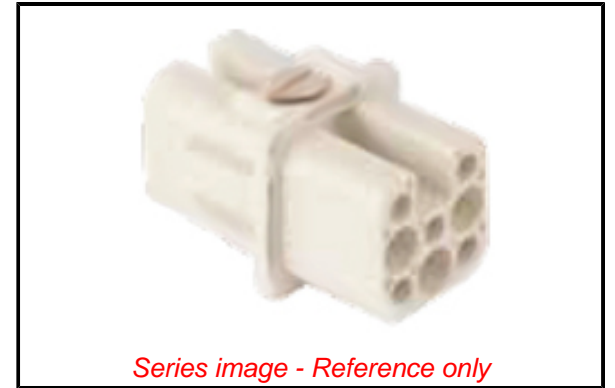

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2022)4187-DC (10
 June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[93601](#) Series

Mates With

[936010084](#) Male Crimp Contact Insert

Use With

Turned Crimp Contacts - Female