

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010702](#)
Status: **Active**
Overview: GWconnect Heavy Duty Connectors (HDC)
Description: GWconnect STD - Standard, Cover for Female Inserts, Die-cast Aluminum, with 2 Pegs, with Gasket, Size 3A «21x21», Grey

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA 256883
 UL E249674

General

Product Family Industrial Connectors / Enclosures
 Series [93601](#)
 Comments With nylon wire tether line.
 Component Size 3A «21x21»
 Component Type Cover
 IP Rating IP66, IP67
 Overview [GWconnect Heavy Duty Connectors \(HDC\)](#)
 Product Category Heavy Duty Connectors
 Product Name GWconnect
 Standard ANSI/UL 50, ANSI/UL 50 E, CSA C22.2 No.94-1-2, EN 61984
 Taxonomy Heavy-Duty Connectors
 Type STD
 UPC 887191843490

Physical


Cover Coating Polyester Powder
 Cover Color Grey RAL 7037
 Lock to Mating Part Yes
 Material - Cover Die-cast Aluminum
 Material - Gasket NBR
 Material - Peg Die-cast Aluminum
 Net Weight 8.800/g
 Number of Pegs 2
 Packaging Type Bag
 Thread Size N/A
 Thread Type N/A

Electrical

Voltage - Maximum 230V / 400V

Material Info

Engineering Number 7803.6802.0

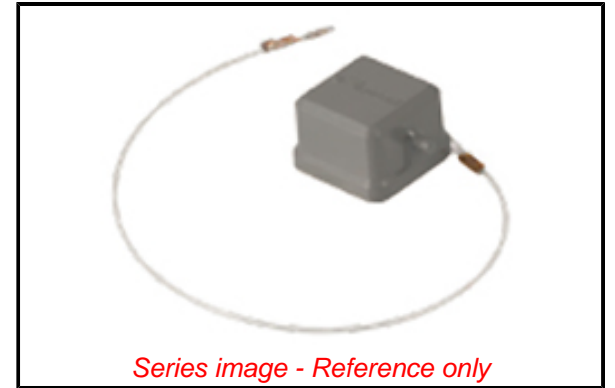

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2022)4187-DC (10
 June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT_CE -

Declaration of

Conformity

China RoHS

Green Image

Not Relevant

Not Contained

CER_4000400719_00_000.pdf

Search Parts in this Series

[93601 Series](#)

Use With

Size 3A «21x21» Housings and Female Inserts