

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010712](#)
Status: **Active**
Overview: GWconnect Heavy Duty Connectors (HDC)
Description: GWconnect STD - Standard, Cover for Female Inserts, Polyamide, with 1 Lever, with Gasket, Size 3A «21x21», Grey

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA 256883
 UL E249674

General

Product Family Industrial Connectors / Enclosures
 Series [93601](#)
 Comments With nylon wire tether line.
 Component Size 3A «21x21»
 Component Type Cover
 IP Rating IP66, IP67
 Overview [GWconnect Heavy Duty Connectors \(HDC\)](#)
 Product Category Heavy Duty Connectors
 Product Name GWconnect
 Taxonomy Heavy-Duty Connectors
 Type STD
 UPC 887191844190

Physical


Cover Color Grey RAL 9002
 Flammability UL 94V-0
 Lock to Mating Part Yes
 Material - Cover Polyamide
 Material - Lever Polyamide
 Net Weight 10.000/g
 Number of Levers 1
 Packaging Type Bag

Material Info

Engineering Number 7803.6879.0

Reference - Drawing Numbers

Sales Drawing 936010712-000

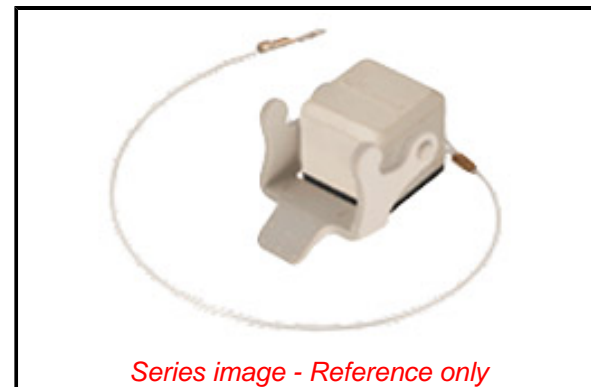

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT_CE -

Declaration of

Conformity

China RoHS

Green Image

Not Relevant

Not Contained

CER_4000400719_00_000.pdf

Search Parts in this Series

[93601 Series](#)

Use With

Enclosures with with Size 3A «21x21»

Female Inserts