

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0936010717](#)  
**Status:** **Active**  
**Overview:** GWconnect Heavy Duty Connectors (HDC)  
**Description:** GWconnect STD - Standard, Cover for Female Inserts, Die-cast Aluminum, with 1 Lever, with Gasket, Size 3A «21x21» Insert, Grey

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA	256883
UL	E249674

**General**


Product Family	Industrial Connectors / Enclosures
Series	<a href="#">93601</a>
Comments	With nylon wire tether line.
Component Size	3A «21x21»
Component Type	Cover
IP Rating	IP66, IP67
Overview	<a href="#">GWconnect Heavy Duty Connectors (HDC)</a>
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Taxonomy	Heavy-Duty Connectors
Type	STD
UPC	887191844848

**Physical**

Cover Coating	Polyester Powder
Cover Color	Grey RAL 9002
Lock to Mating Part	Yes
Material - Cover	Die-cast Aluminum
Material - Lever	Stainless Steel
Net Weight	18.000/g
Number of Levers	1
Packaging Type	Bag

**Material Info**

Engineering Number	7803.6884.A
--------------------	-------------

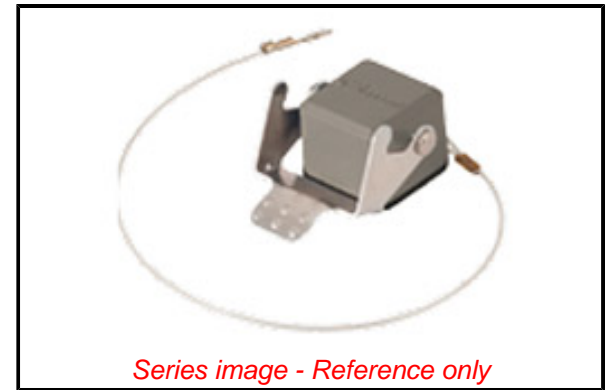

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2022)4187-DC (10  
June 2022)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT\_CE -

Declaration of

Conformity

**China RoHS**

Green Image

Not Relevant

Not Contained

CER\_4000400719\_00\_000.pdf

**Search Parts in this Series**

[93601 Series](#)

**Use With**

Enclosures with with Size 3A «21x21»  
Female Inserts