

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936013334](#)
Status: **Active**
Overview: GWconnect Heavy Duty Connectors (HDC)
Description: GWconnect STD - Standard, Double Locking Cover, Die-cast Aluminum, with 4 Pegs, with Gasket, Size 24B «104x27», Grey

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA 256883
 UL E249674

General

Product Family Industrial Connectors / Enclosures
 Series [93601](#)
 Comments With nylon wire tether line.
 Component Size 24B «104X27»
 Component Type Cover
 IP Rating IP66
 Overview [GWconnect Heavy Duty Connectors \(HDC\)](#)
 Product Category Heavy Duty Connectors
 Product Name GWconnect
 Taxonomy Heavy-Duty Connectors
 Type STD
 UPC 887191884752

Physical


Cover Coating Polyester Powder
 Cover Color Grey RAL 7037
 Lock to Mating Part Yes
 Material - Cover Die-cast Aluminum
 Material - Peg Stainless Steel
 Net Weight 75.000/g
 Number of Pegs 4
 Packaging Type Bag

Electrical

Voltage - Maximum 500V

Material Info

Engineering Number 7824.5122.0

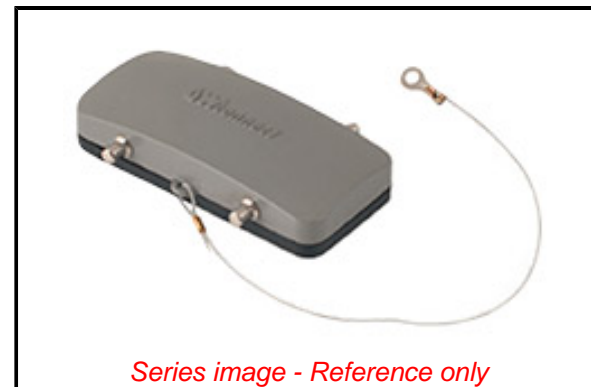

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2022)4187-DC (10
 June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT_CE -

Declaration of

Conformity

Green Image

Not Relevant

Not Contained

CER_4000400780_00_000.pdf

Search Parts in this Series

[93601](#) Series

Use With

Size 24B «104x27» Inserts with 4 Pegs