

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301540063](#)
Status: **Active**
Overview: [Heavy-Duty Industrial Wiring Devices](#)
Description: Super-Safeway® Molded W Cordset, 2 Pole/3 Wire SJOW Cordset, Cordset Length 0.91m (3.0'), NEMA L5-20, 125V, Inline GFCI

Documents:

[RoHS Certificate of Compliance \(PDF\)](#) [Product Literature \(PDF\)](#)

General

Product Family	Wiring Devices
Series	130154
IP Rating	N/A
NEMA Configuration	NEMA L5-20
Overview	Heavy-Duty Industrial Wiring Devices
Product Literature Order No	987650-8068
Product Name	Super-Safeway™
Receptacle Type	Triple
Specialty	N/A
Type	Molded W Cordset
UPC	78678838925
Woodhead	Yes

Physical


Flange	No
Flip Lid	No
Gender	Male-Female
Length	0.91m (3.0')
Locking Blade	Yes
Poles	2-pole/3-wire

Electrical

Cord Type	12/3 SJOW
Current - Maximum per Contact	20.0A
GFCI	Yes-In-line
Lighted Connector	No
Voltage - Maximum	125V

Material Info

Engineering Number	2647-W-IN
--------------------	-----------

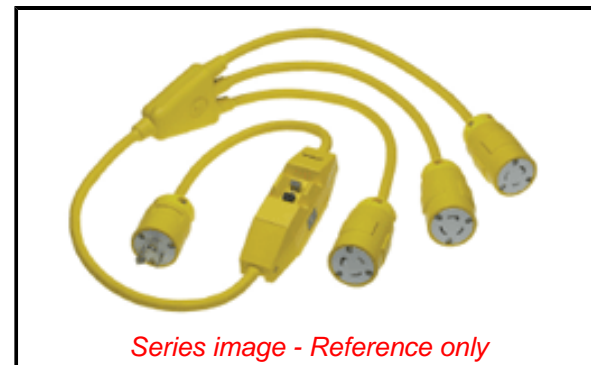

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[130154 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION