


REV. 0
DCO 15282

COIL: @ 25°C
 RESISTANCE 1500 OHMS ± 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 13.5 VDC
 MUST RELEASE 10.0 VDC MAX, 1.5 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 6 ± 1 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE TIME 4 MS MAX.
CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

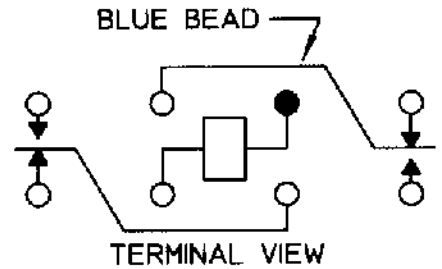

CONTACT RATING: LOW LEVEL TO
1 AMP 28 VDC RESISTIVE
100,000 OPERATIONS

DR. R.B. 4/8/99 CK. *[Signature]*

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. OPL
 CUST. NO. M39016/34-012

TYPE 'MFW' RELAY

REVISION
MFW1201N04