

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **1200798010**
Status: **Active**
Overview: Brad Ultra-Lock Connection System
Description: Ultra-Lock (M12) Single-Ended Cordset, 4 Poles, Female (Straight) to Pigtail, 22 AWG, PUR/PVC Cable, 10.0m (32.81') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Cordsets
Series	120079
Connector End A	Ultra-Lock (M12)
Connector End B	Pigtail
IP Rating	IP69K
Material - Contact	Copper Alloy
Overview	Brad Ultra-Lock Connection System
Product Name	Ultra-Lock (M12)
Protocol	EtherNet
Region	Europe
Taxonomy	Circular Industrial Cordsets
Type	Single Ended
UPC	883906712112

Physical

Cable Diameter	5.30mm (.209")
Cable Length	10.0m (32.81')
Color - Cable Jacket	Black
Coupling Style	Push to Lock
Gender	Female-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PUR/PVC
Material - Connector Body	PUR
Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Net Weight	401.000/g
Orientation	Straight to Pigtail
Poles	4
Temperature Range - Operating	-20° to +80°C
Wire Size AWG	22
Wire/Cable Type	EU Cable

Electrical


Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC

Material Info

Engineering Number	W04000P03M100
--------------------	---------------

Reference - Drawing Numbers

Sales Drawing	1200795043-000, SD-120079-014-001
---------------	-----------------------------------

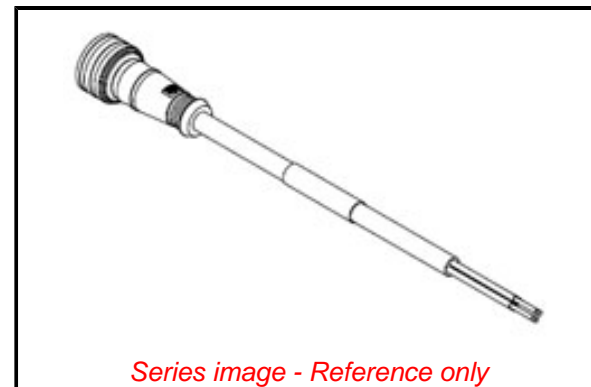

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per -
D(2022)4187-DC (10
June 2022)

Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

120079 Series