

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200900037](#)
Status: **Active**
Overview: [Brad Nano-Change \(M8\) Products](#)
Description: Nano-Change (M8) Receptacle, 5 Poles, M8 x 0.5 Mounting Threads, Female (Straight) to 22 AWG Leads, 0.30m (11.81") Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E46237

General

Product Family Industrial Receptacles
 Series [120090](#)
 IP Rating IP67
 NEMA Rating NEMA 6
 Overview [Brad Nano-Change \(M8\) Products](#)
 Product Name Nano-Change (M8)
 Taxonomy Circular Industrial Connectors
 Type Single Ended (pigtail)
 UPC 78678833576

Physical

Coupling Type Internal Thread
 Gender Female
 Keyway B-coded
 Length 0.30m
 Material - Component Nickel-plated Brass
 Mounting Thread Size M8 x 0.5
 Net Weight 10.284/g
 Orientation Straight
 Panel Mount Front
 Poles 5
 Temperature Range - Operating -20° to +105°C
 Wire Size AWG 24
 Wire/Cable Type UL 1569

Electrical


Current - Maximum per Contact 3.0A
 Voltage - Maximum 60V AC / 75V DC

Material Info

Engineering Number 4R5P00A27C300

Reference - Drawing Numbers

Sales Drawing 1200908076-000, SD-120090-009-001

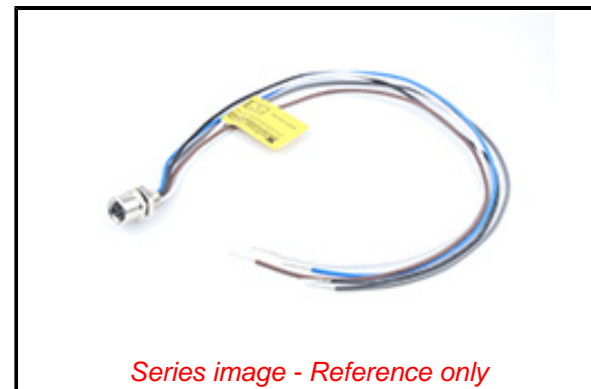

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2022)4187-DC (10 June 2022)

Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT_CE -

Declaration of

Conformity

ZZCERT_UKCA

- Declaration of

Conformity

China RoHS

50 Image

Not Relevant

Not Contained

CER_4000408918_00_000.pdf

CER_4000410285_00_000.pdf

Search Parts in this Series

[120090 Series](#)