

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1200980111](#)  
**Status:** **Active**  
**Overview:** Brad Micro-Change (M12) Connectors  
**Description:** Micro-Change (M12) Single-Ended Cordset, 5 Poles, Male (90°) to Pigtail, 24 AWG, 5.0m (16.40') Length, PROFIBUS PUR Cable Preferred Version in Europe

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Industrial Cordsets
Series	<a href="#">120098</a>
Connector End A	Micro-Change (M12)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	<a href="#">Brad Micro-Change (M12) Connectors</a>
Product Name	Micro-Change (M12)
Protocol	EtherNet
Region	America, Asia, Europe
Taxonomy	Circular Industrial Cordsets
Type	Single Ended
UPC	78678850777

**Physical**

Cable Diameter	8.00mm (.315")
Cable Length	5.0m (16.40')
Color - Cable Jacket	Purple
Coupling Style	Threaded
Gender	Male-Pigtail
Keyway	Reverse
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PUR
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Orientation	90° to Pigtail
Poles	5
Temperature Range - Operating	-20° to +80°C
Wire Size AWG	24
Wire/Cable Type	Twisted Pair

**Electrical**


Current - Maximum per Contact	3.0A
Voltage - Maximum	60V AC/DC

**Material Info**

Engineering Number	B05S07PP4M050
--------------------	---------------

**Reference - Drawing Numbers**

Sales Drawing	SD-120039-004-001
---------------	-------------------

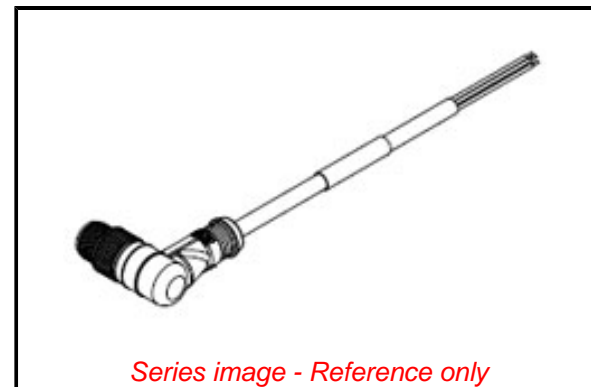

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Not Contained Per -ED/01/2017 (12 January 2017)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT\_UKCA

- Declaration of

Conformity

**China RoHS**

50 Image

Not Relevant

Not Contained

CER\_4000406115\_00\_000.pdf

**Search Parts in this Series**

[120098 Series](#)