

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1201010001](#)
Status: **Active**
Description: PROFIBUS Data Line Mini-Change Tee, 5 Poles, Female/Male with Female Drop

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E152210

General

Product Family Industrial Tees and Splitters
 Series [120101](#)
 IP Rating IP67
 Product Name PROFIBUS Data Line
 Taxonomy Industrial Tees and Splitters
 Type Power Tap Tee
 UPC 78678850377

Physical

Drop Connector Mini-Change
 Drop Gender Female
 Keyway Single
 LED Indicator No
 Left Trunk Connector Mini-Change
 Left Trunk Gender Female
 Leg 1 Length N/A
 Leg 2 Length N/A
 Material - Cable Jacket N/A
 Material - Connector Body TPE
 Material - Coupling Nut Black Epoxy Coated Zinc
 Net Weight 176.670/g
 Poles 5
 Right Trunk Connector Mini-Change
 Right Trunk Gender Male
 Temperature Range - Operating -20°C to +80°C

Electrical


Current - Maximum per Contact 8.0A
 Voltage - Maximum 600V AC/DC

Material Info

Engineering Number PBAPT

Reference - Drawing Numbers

Sales Drawing SD-120101-002-001

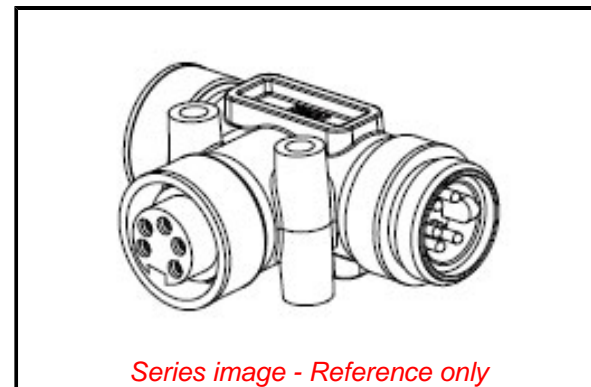

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2022)4187-DC (10 June 2022)
 Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT_CE -

Declaration of

Conformity

ZZCERT_UKCA

- Declaration of
 Conformity

China RoHS

50 Image

Not Relevant

Not Contained

CER_4000408918_00_000.pdf

CER_4000410285_00_000.pdf

Search Parts in this Series

[120101 Series](#)