

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1201020002](#)
Status: **Active**
Overview: PROFIBUS Solutions
Description: PROFIBUS Micro-Change (M12) Terminator Shield, 5 Poles

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Field Attachable / Accessories
Series	120102
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	PROFIBUS Solutions
Product Name	PROFIBUS
Taxonomy	Circular Industrial Connectors
Type	Terminator
UPC	78678849805

Physical

Cable Diameter	N/A
Coupling Type	External Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Male
Keyway	Single
Material - Connector Body	PVC
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	19.970/g
Orientation	Straight
Poles	5
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	N/A

Electrical


Current - Maximum per Contact	3.0A
Voltage - Maximum	250V AC/DC

Material Info

Engineering Number	B05S06
--------------------	--------

Reference - Drawing Numbers

Sales Drawing	SD-120102-001-001
---------------	-------------------

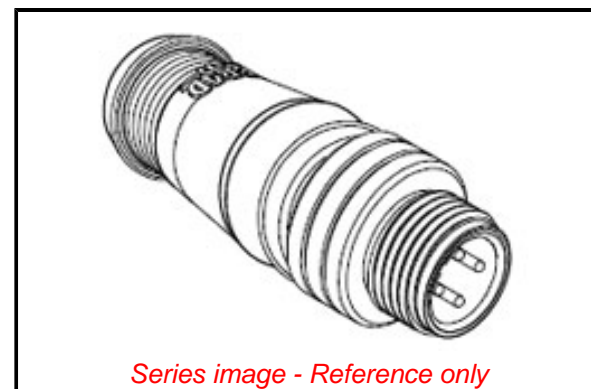

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Contained Per -
D(2020)9139-DC (19
Jan 2021)

Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[120102 Series](#)