

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1201080203](#)
Status: **Active**
Overview: Brad Industrial Ethernet Solutions
Description: Micro-Change (M12) to RJ-45 Double-Ended Cordset, 4 Poles, Male (Straight) to Male RJ-45, 22 AWG, Shielded PUR Cable, 2.0m (6.56') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E361772

General

Product Family	Industrial Cordsets
Series	120108
Connector End A	Micro-Change (M12)
Connector End B	RJ-45 (standard)
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Industrial Ethernet Solutions
Performance Category	5e
Product Name	Micro-Change (M12)
Region	America, Asia, Europe
Taxonomy	Circular Industrial Cordsets
Type	Double Ended
UPC	78172535392

Physical

Cable Diameter	6.70mm (.264")
Cable Length	2.0m (6.56')
Color - Cable Jacket	Green
Coupling Style	Threaded
Gender	Male-Male
Keyway	N/A
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PUR
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	165.177/g
Orientation	Straight to Straight
Poles	4
Temperature Range - Operating	-20° to +60°C
Wire Size AWG	22
Wire/Cable Type	Shielded PUR

Electrical


Current - Maximum per Contact	1.5A
Voltage - Maximum	30V

Material Info

Engineering Number E16A06011M020

Reference - Drawing Numbers

Sales Drawing 1201080256-000

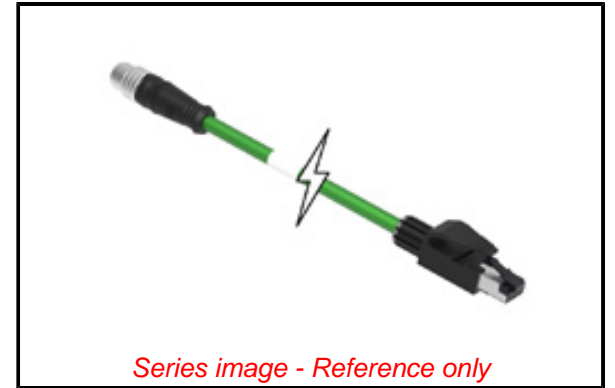

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

ZZCERT_CE -

CER_4000410036_00_000.pdf

Declaration of

Conformity

ZZCERT_UKCA

CER_4000410293_00_000.pdf

- Declaration of

Conformity

Search Parts in this Series

120108 Series

This document was generated on 09/01/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION