

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1201080246](#)
Status: **Active**
Overview: Brad Industrial Ethernet Solutions
Description: Micro-Change (M12) Double-Ended Cordset, 4 Poles, Male (Straight) to Male (Straight), 22 AWG, Shielded PUR Cable, 15.0m (49.21') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E361772

General

Product Family	Industrial Cordsets
Series	120108
Connector End A	Micro-Change (M12)
Connector End B	Micro-Change (M12)
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Industrial Ethernet Solutions
Performance Category	5e
Product Name	Micro-Change (M12)
Region	America, Asia, Europe
Taxonomy	Circular Industrial Cordsets
Type	Double Ended
UPC	78172536919

Physical

Cable Diameter	6.70mm (.264")
Cable Length	15.0m (49.21')
Color - Cable Jacket	Green
Coupling Style	Threaded
Gender	Male-Male
Keyway	D-coded
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PUR
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	1009.463/g
Orientation	Straight to Straight
Poles	4
Temperature Range - Operating	-20° to +60°C
Wire Size AWG	22
Wire/Cable Type	Shielded PUR

Electrical


Current - Maximum per Contact	1.5A
Voltage - Maximum	30V

Material Info

Engineering Number E11A06011M150

Reference - Drawing Numbers

Sales Drawing SD-120108-041-001

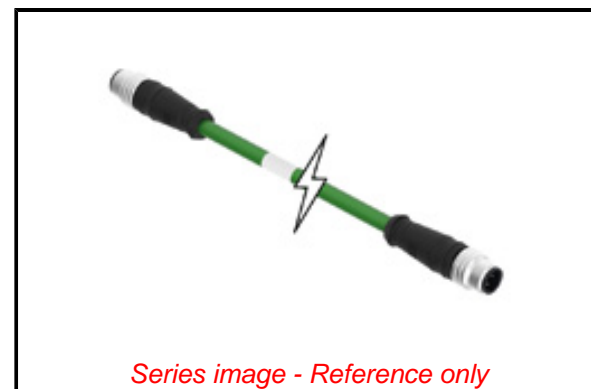

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2020)4578-DC (25 June 2020)

Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT_CE -

Declaration of

Conformity

China RoHS

50 Image

Not Relevant

Not Contained

CER_4000410038_00_000.pdf

Search Parts in this Series

120108 Series

This document was generated on 09/03/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION