

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1201150054](#)
Status: **Active**
Overview: Brad Micro-Change (M12) Connectors
Description: Micro-Change Molded Junction Box with Molded Cable, Side Mount, 8 Ports, PNP, 5.0m Cable Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Passive Distribution Boxes
Series	120115
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Taxonomy	Passive Distribution Boxes
UPC	78678824066

Physical

Bus I/O	Micro-Change (M12)
Cable Connector Orientation	Straight
Cable Length	5.0m
Home Run Cable Length	N/A
Home Run Connector	N/A
Home Run Interface	N/A
Keyway	Single
LED Indicator	PNP Sensors
Material - Cable Jacket	PVC
Material - Housing	PBT
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Orientation	Side Mount
Poles	5
Poles (wired)	4
Ports	8
Temperature Range - Operating	-20°C to +90°C
Wiring Configuration	Single I/O per Port

Electrical


Current - Maximum per Contact	4.0A per port
Functional Wiring	PNP
Voltage - Maximum	10-30V DC

Material Info

Engineering Number	803P801
--------------------	---------

Reference - Drawing Numbers

Sales Drawing	SD-120115-007-001
---------------	-------------------

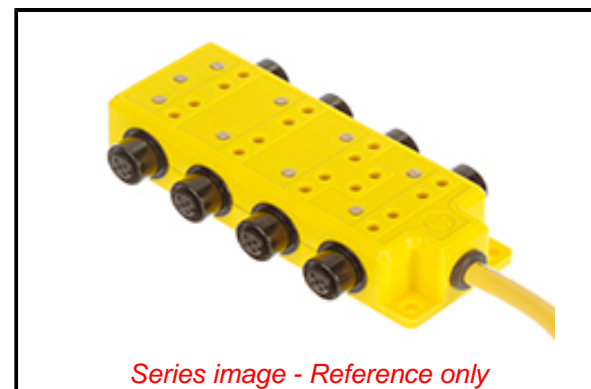

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

China RoHS

Search Parts in this Series

[120115 Series](#)